

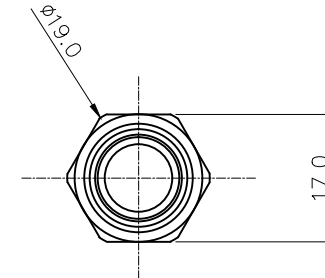


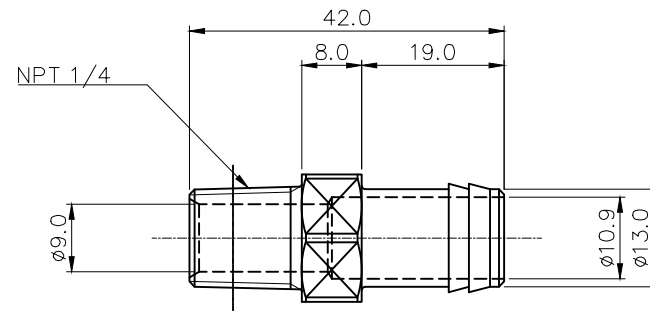

Single hose barb fitting for 1/2in (13mm) ID tubing. 1/4 NPT (tapered) thread. Hose clamp is included for 5/8in (16mm) OD tubing.

General	
Weight	0.07 lb (0.03 kg)
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	SUS 316, EPDM

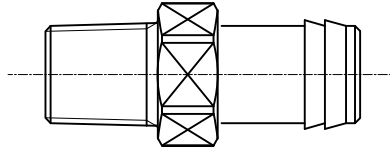

△	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY
REVISION					

NO.		DESCRIPTION		MATER'L		QUANTITY	REMARKS
KOOLANCE		UNIT		MM	ITEM FIT-V13N14-SS		
		SCALE		N/S	TITLE		
DATE	BY	BY	BY	APPRD BY	3RD ANGLE		
	ys.shin				CODE NO.		DWG. NO.
							PAGE
							-