





Single hose barb fitting for 1/2in (13mm) ID tubing. G 1/4 BSPP (parallel) thread. Hose clamp is included for 5/8in (16mm) OD tubing.

General	
Weight	0.04 lb (0.02 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Brass, Nickel Plating, EPDM

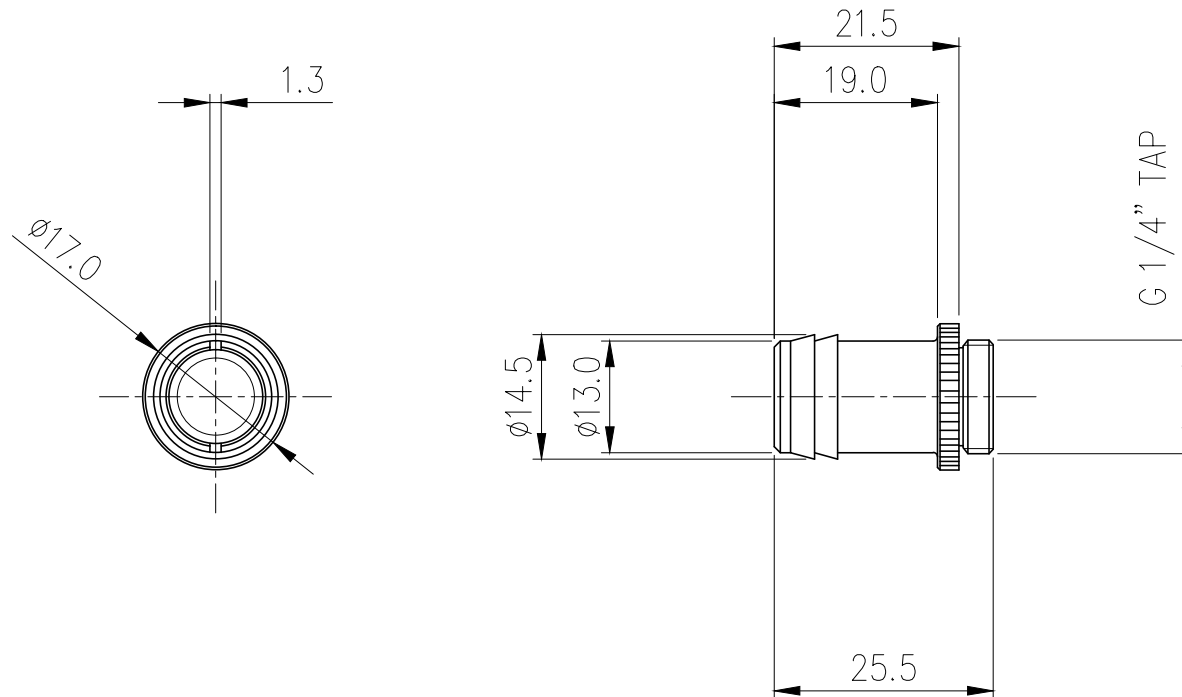

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS
		BY		BY	BY	APPRO	UNIT	MM	APPAR NZL-V13B(-BK)
		DATE		04/21/2017	S.J.LEE		SCALE	N/S	TITLE
							3RD ANGLE		Ass'y
							CODE NO.		DWG. NO.