





Single hose barb fitting for 1/2in (13mm) ID tubing. G 1/4 BSPP (parallel) thread. Hose clamp is included for 5/8in (16mm) OD tubing.

| General                        |                             |
|--------------------------------|-----------------------------|
| Weight                         | 0.04 lb (0.02 kg)           |
| Fitting Thread                 | G 1/4 BSPP                  |
| Max Pressure Tolerance @ 25° C | 15kgf/cm2 (213.4psi)        |
| Max Temperature Tolerance      | 120° C (248° F)             |
| Wetted Materials               | Brass, Nickel Plating, EPDM |

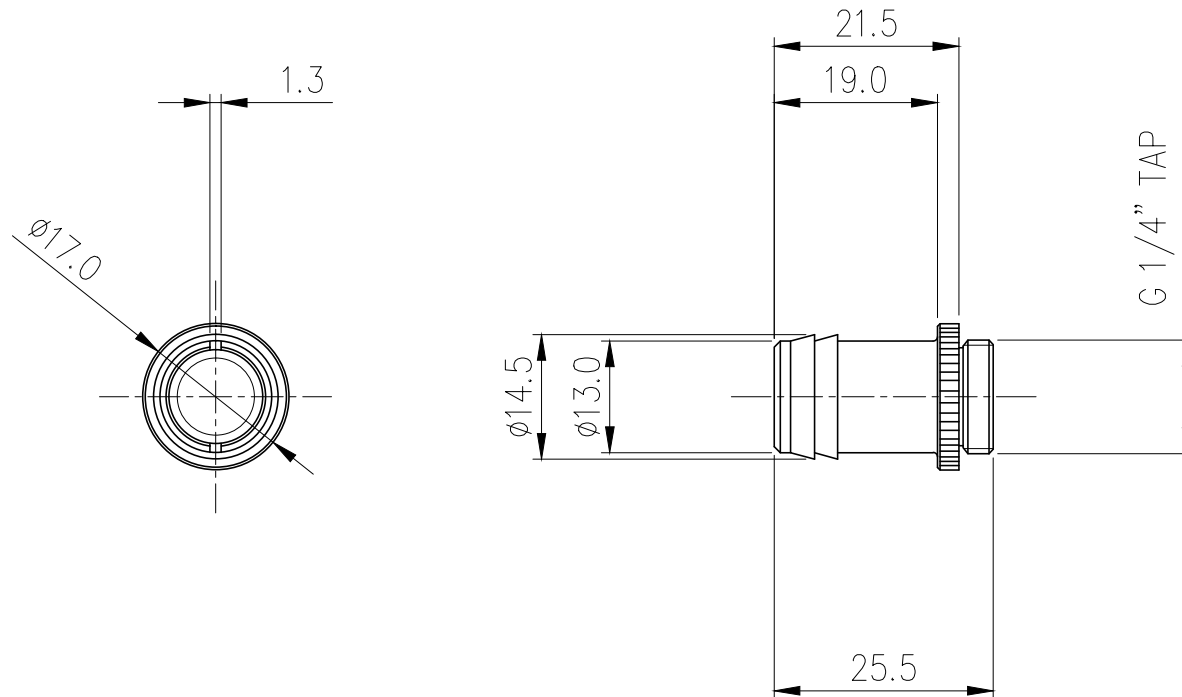

| NO.   |  | DESCRIPTION |  |         |  | MATER'L    |  | QUANTITY  | REMARKS       |
|---|--|-------------|--|---------|--|------------|--|-----------|---------------|
|  |  | BY          |  | BY      |  | APPRO      |  | UNIT      | MM            |
|   |  | DATE        |  | S.J.LEE |  | 04/21/2017 |  | SCALE     | N/S           |
|   |  |             |  |         |  |            |  | 3RD ANGLE | TITLE         |
|   |  |             |  |         |  |            |  | CODE NO.  | DWG. NO.      |
|   |  |             |  |         |  |            |  |           | Ass'y         |
|   |  |             |  |         |  |            |  |           | NZL-V13B(-BK) |