



Barb Fitting for ID 10mm (3/8in) \*Black\*, G 1/4  
BSPP



Single hose barb fitting for 3/8in (10mm) ID tubing. G 1/4 BSPP (parallel) thread. Includes hose clamp for 1/2in (13mm) OD tubing.

| General                        |                      |
|--------------------------------|----------------------|
| Weight                         | 0.03 lb (0.01 kg)    |
| Fitting Thread                 | G 1/4 BSPP           |
| Max Pressure Tolerance @ 25° C | 15kgf/cm2 (213.4psi) |
| Max Temperature Tolerance      | 120° C (248° F)      |
| Wetted Materials               | Brass, EPDM          |

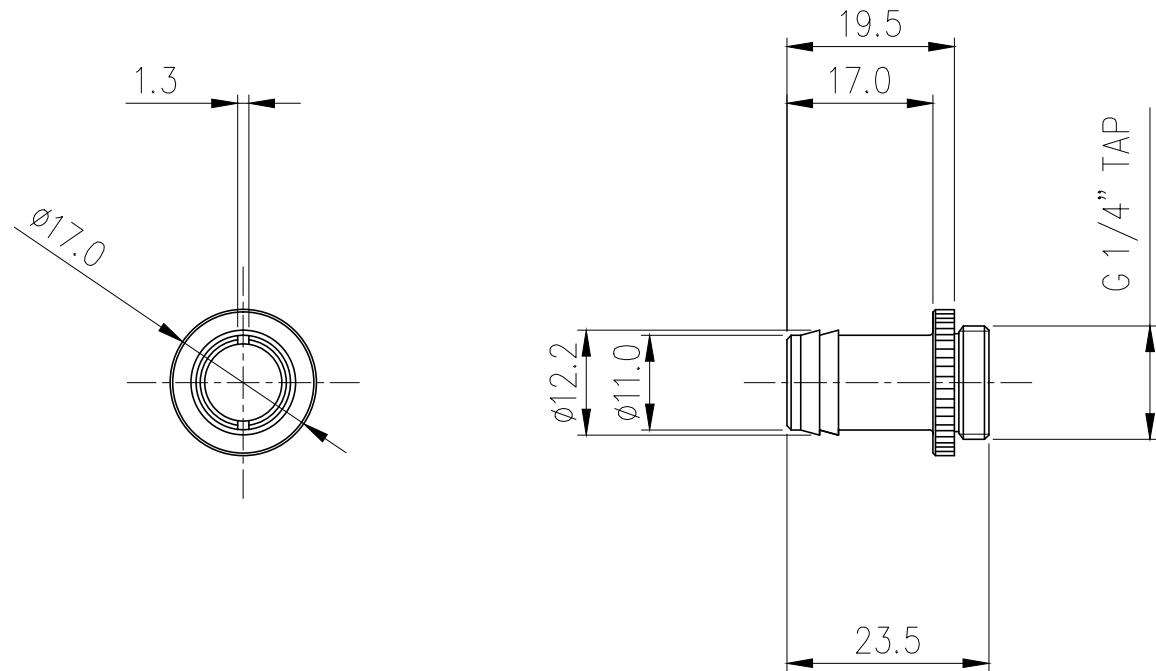

|   |         |             |    |          |           |         |          |                     |         |
|---|---------|-------------|----|----------|-----------|---------|----------|---------------------|---------|
|   |         |             |    |          |           |         |          |                     |         |
| NO.   |         | DESCRIPTION |    |          |           | MATER'L |          | QUANTITY            | REMARKS |
|  |         |             |    |          |           | UNIT    | MM       | APPAR NZL-V10B(-BK) |         |
|   |         |             |    |          |           | SCALE   | N/S      | TITLE<br><br>Ass'y  |         |
| DATE  | BY      | BY          | BY | APPRO BY | 3RD ANGLE |         |          |                     |         |
| 04/21/2017  | S.J.LEE |             |    |          | CODE NO.  |         | DWG. NO. |                     |         |
|   |         |             |    |          |           |         |          |                     |         |