
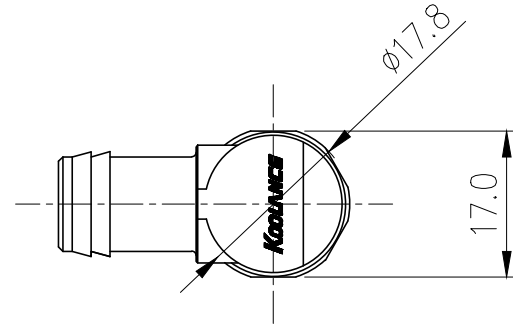
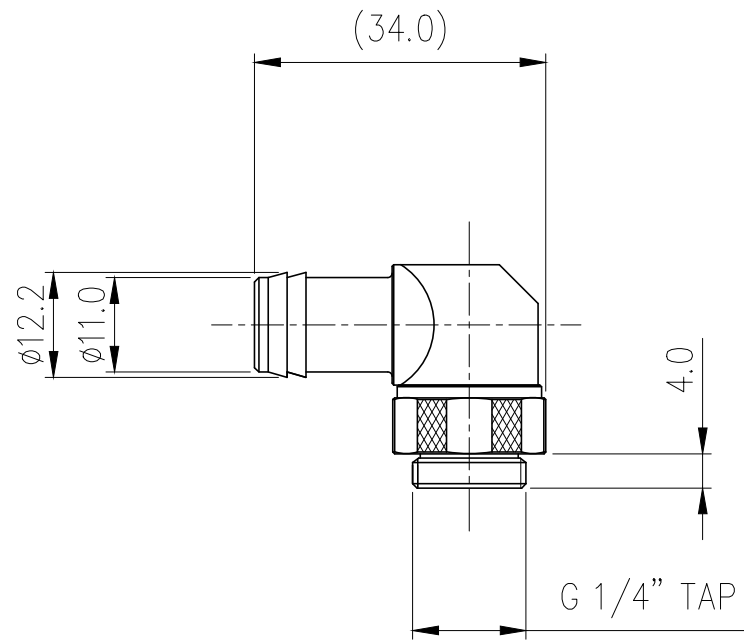



**Rotary Elbow Barb Fitting for ID 10mm (3/8in)  
\*Black\*, G 1/4 BSPP**

Single rotational angled fitting barb for 3/8in (10mm) ID tubing. G 1/4 BSPP (parallel) thread. Made of brass and includes hose clamp.

General	
Weight	0.08 lb (0.04 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25°C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100°C (212°F)
Wetted Materials	Brass, EPDM

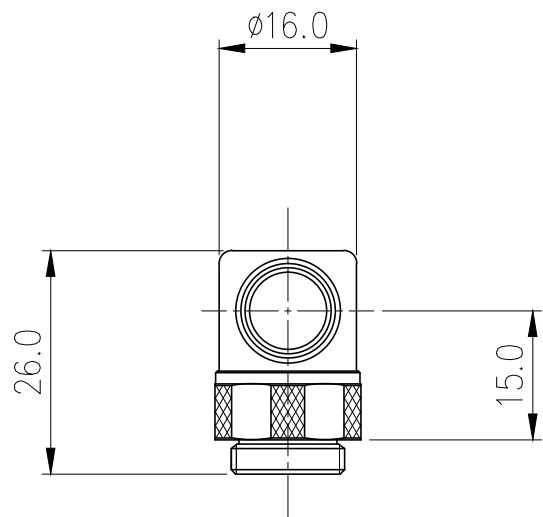

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
					UNIT	MM	APPAR NZL-L10B(-BK)	
					SCALE	N/S	TITLE  Ass'y	
	BY	BY	BY	APPRO BY	3RD ANGLE			
DATE					CODE NO.			
04/13/2017	S.J.LEE				DWG. NO.			