
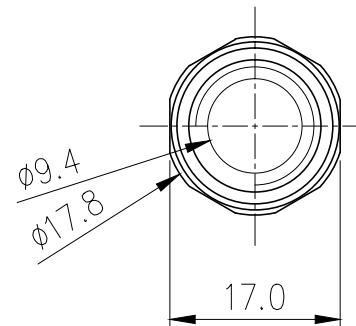
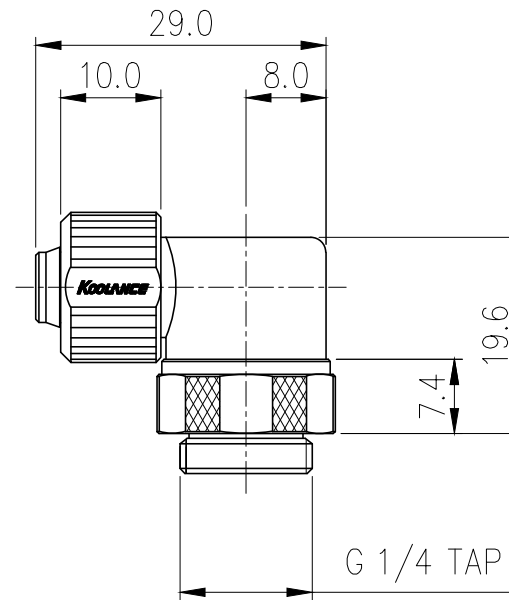


**Rotary Elbow \*Black\* Compression Fitting for  
06mm x 10mm (1/4in x 3/8in), G 1/4 BSPP**

Single rotational angled fitting for 1/4in (6mm) ID, 3/8in (10mm) OD tubing. G 1/4 BSPP (parallel) thread.

General	
Weight	0.09 lb (0.04 kg)
Max Pressure Tolerance @ 25°C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100°C (212°F)
Wetted Materials	Brass, EPDM

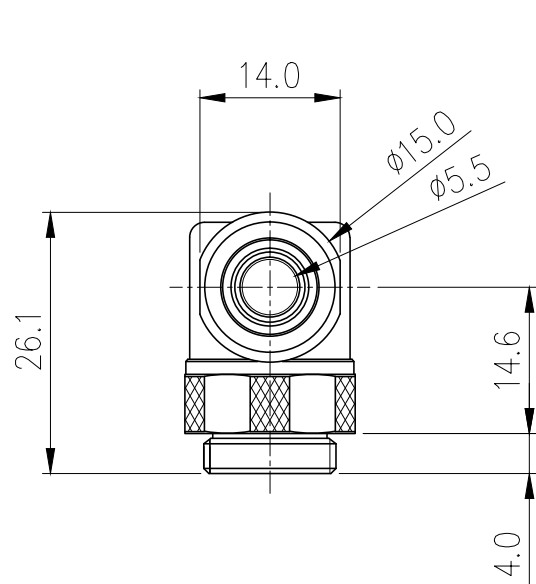

REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY
REVISION					

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
<b>KOOLANCE</b>					UNIT	MM	APPAR	NZL-L06
					SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRD BY	3RD ANGLE		Ass'y	
	S.J.LEE				REV.	NO.	DWG. NO.	
						20		