

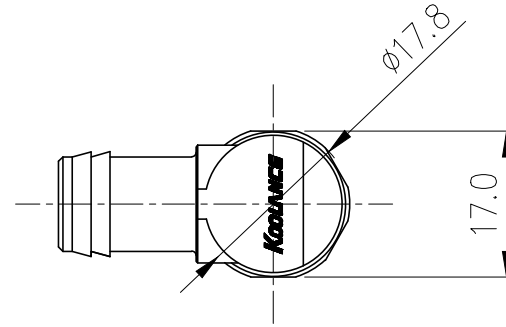



Rotary Elbow Barb Fitting for ID 10mm (3/8in),  
G 1/4 BSPP

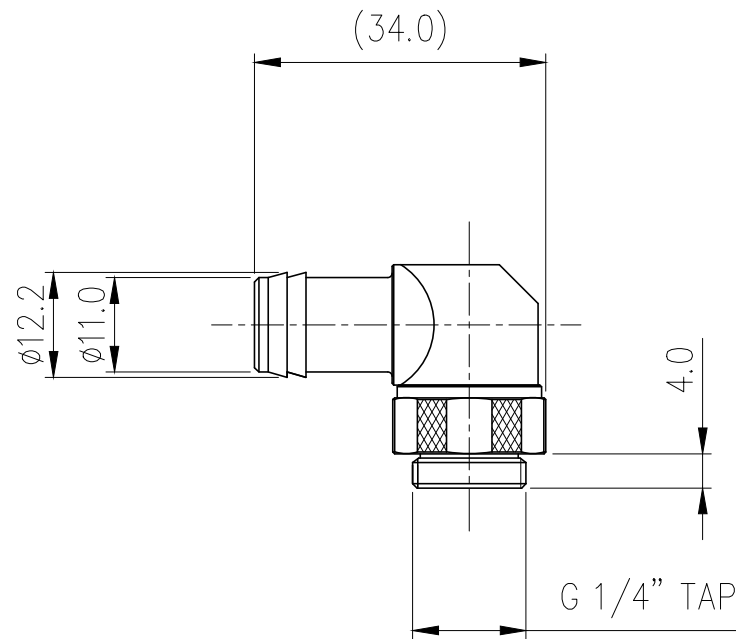

Single rotational angled fitting barb for 3/8in (10mm) ID tubing. G 1/4 BSPP (parallel) thread. Spring clamp included for 1/2in (13mm) OD tubing.

General	
Weight	0.08 lb (0.04 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100° C (212° F)
Wetted Materials	Brass, Nickel Plating, EPDM

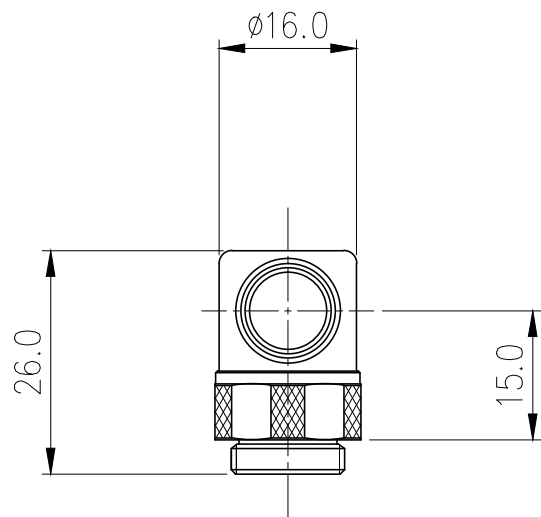

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS
		BY		BY	BY	UNIT	MM	APPAR	NZL-L10B(-BK)
		DATE		DATE	DATE	SCALE	N/S	TITLE	
04/13/2017		S.J.LEE				3RD ANGLE		Ass'y	
						CODE NO.		DWG. NO.	