




Rotary Elbow Barb Fitting for ID 13mm (1/2in),  
G 1/4 BSPP

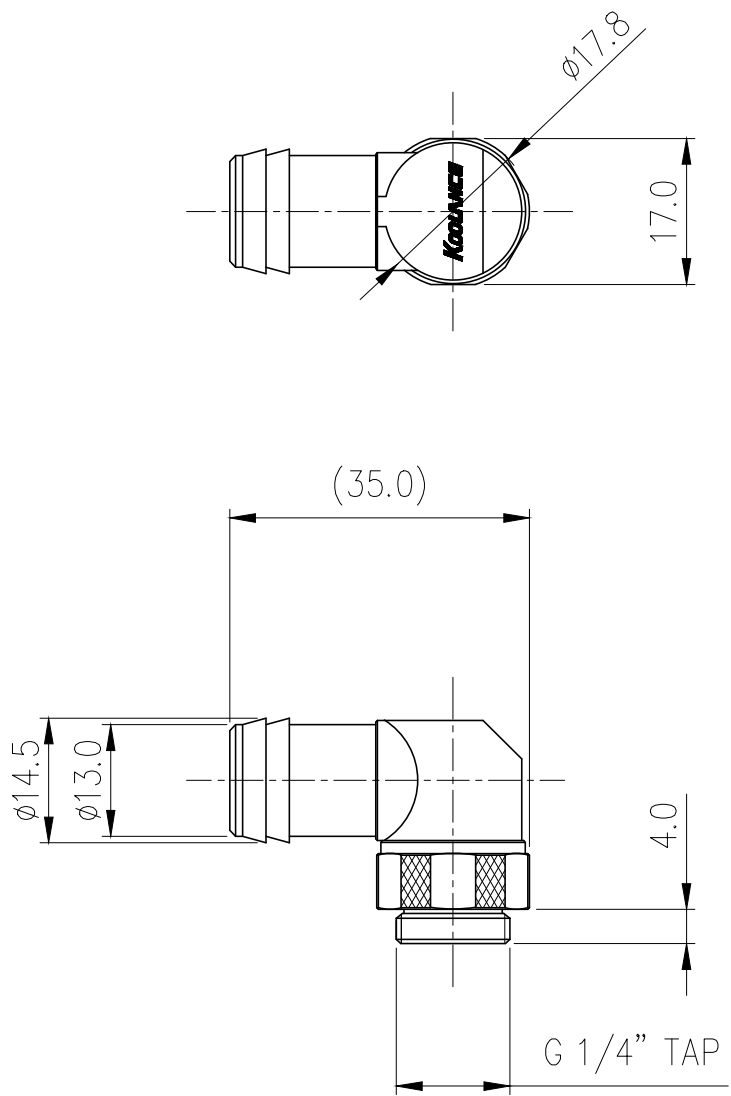

Single rotational angled fitting barb for 1/2in (13mm) ID tubing. G 1/4 BSPP (parallel) thread. Spring clamp included for 5/8in (16mm) OD tubing.

| General                        |                             |
|--------------------------------|-----------------------------|
| Weight                         | 0.09 lb (0.04 kg)           |
| Fitting Thread                 | G 1/4 BSPP                  |
| Max Pressure Tolerance @ 25° C | 8kgf/cm2 (113.8psi)         |
| Max Temperature Tolerance      | 100° C (212° F)             |
| Wetted Materials               | Brass, Nickel Plating, EPDM |

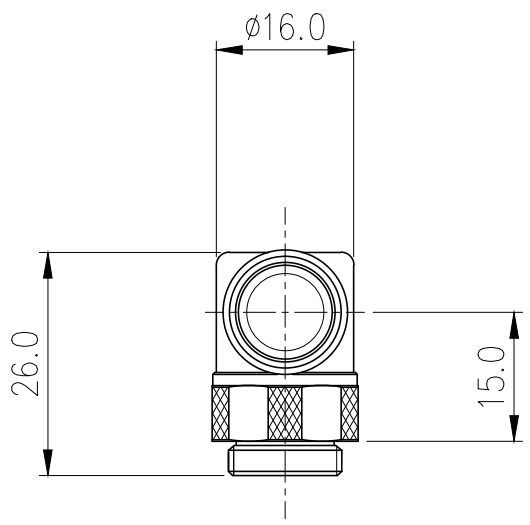

| NO.        | DESCRIPTION   | MATER'L |     | QUANTITY | REMARKS       |
|------------|---|---------|-----|----------|---------------|
|            |  | UNIT    | MM  | APPAR    | NZL-L13B(-BK) |
|            |   | SCALE   | N/S | TITLE    |               |
| DATE       | BY  | BY      | BY  | BY       | 3RD ANGLE     |
| 04/13/2017 | S.J.LEE   |         |     |          | DWG. NO.      |
|            |   |         |     |          | Ass'y         |