




Swivel/Lock Barb Fitting for ID 10mm (3/8in), G  
1/4 BSPP

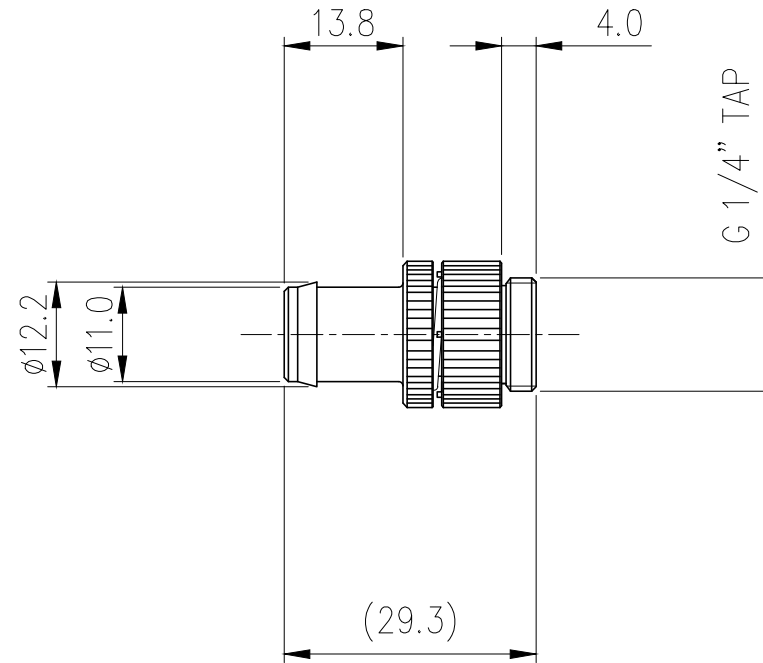

Single hose barb fitting for 3/8in (10mm) ID tubing. This fitting swivels to relieve hose stress and accidental loosening. To tighten or untighten, simply push in on the fitting and twist. G 1/4 BSPP (parallel) thread. Hose clamp included for 1/2in (13mm) OD tubing.

General	
Weight	0.05 lb (0.02 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100° C (212° F)
Wetted Materials	Brass, Nickel Plating, EPDM

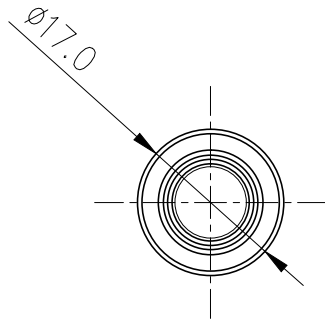

NO.		DESCRIPTION			MATER'L		QUANTITY		REMARKS	
					UNIT	MM	APPAR NZL-V10BS			
					SCALE	N/S	TITLE			
DATE		BY	BY	BY	APPRO BY	3RD ANGLE		Ass'y		
04/22/2017		S.J.LEE				CODE NO.		DWG. NO.		