



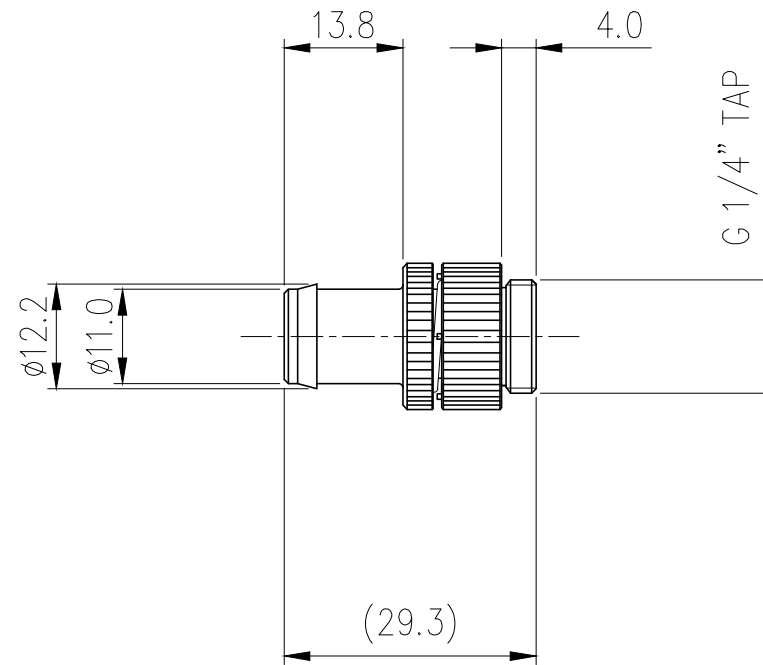


Single hose barb fitting for 3/8in (10mm) ID tubing. This fitting swivels to relieve hose stress and accidental loosening. To tighten or untighten, simply push in on the fitting and twist. G 1/4 BSPP (parallel) thread. Hose clamp included for 1/2in (13mm) OD tubing.

General	
Weight	0.05 lb (0.02 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100° C (212° F)
Wetted Materials	Brass, Nickel Plating, EPDM

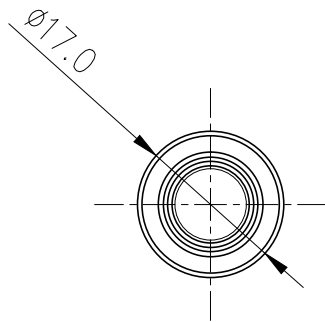

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS
						UNIT	MM	APPAR NZL-V10BS	
						SCALE	N/S	TITLE Ass'y	
DATE		BY		BY		3RD ANGLE			
04/22/2017	S.J.LEE					CODE NO.		DWG. NO.	