



**Swivel/Lock Barb Fitting for ID 13mm (1/2in), G
1/4 BSPP**



Single hose barb fitting for 1/2in (13mm) ID tubing. This fitting swivels to relieve hose stress and accidental loosening. To tighten or untighten, simply push in on the fitting and twist. G 1/4 BSPP (parallel) thread. Hose clamp included for 5/8in (16mm).

General	
Weight	0.06 lb (0.03 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	100° C (212° F)
Wetted Materials	Brass, Nickel Plating, EPDM

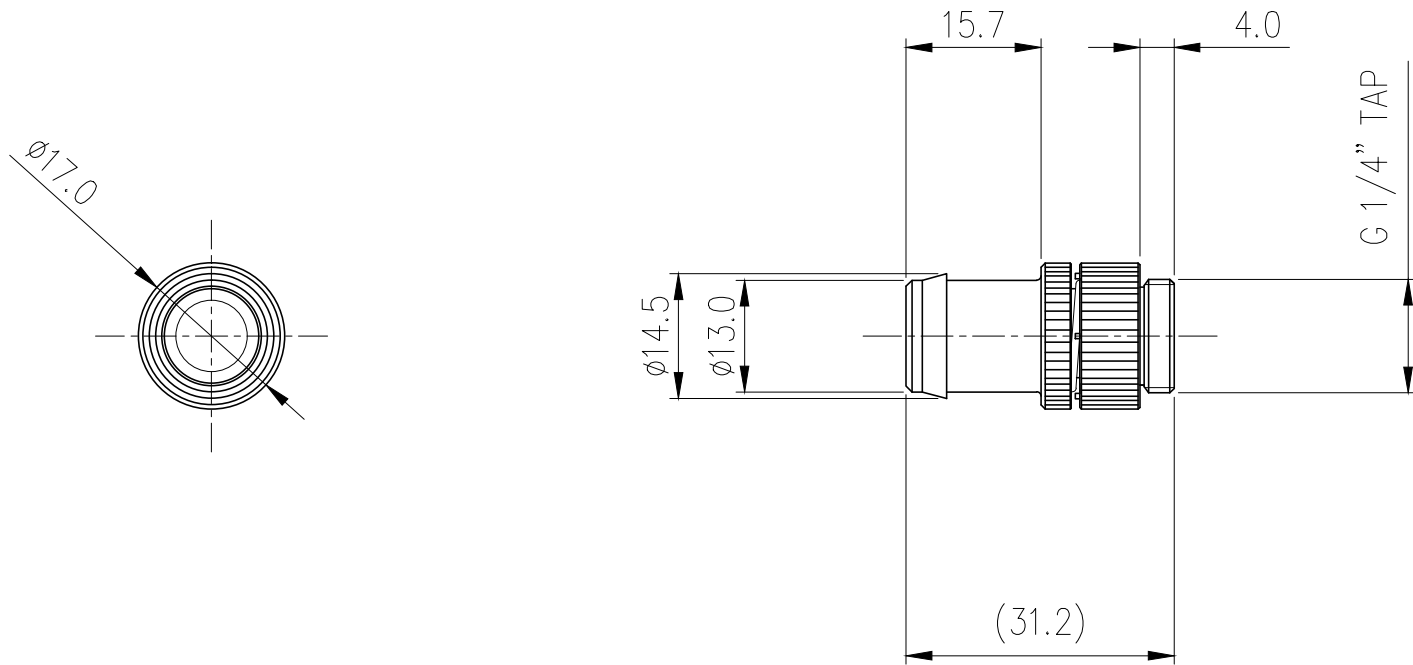

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS
						UNIT	MM	APPAR	NZL-V13BS
						SCALE	N/S	TITLE	
DATE		BY	BY	BY	APPRO BY	3RD ANGLE		Ass'y	
04/22/2017		S.J.LEE				CODE NO.		DWG. NO.	