



Large dual CPU systems are accommodated by the PC3-726, which provides support for motherboards up to 12" x 13" (30.5cm x 33cm). This model does *not* include a side window.

An ultimate combination of cooling power in aluminum! Koolance's PC3-726 includes the new 700W pro cooling system merged with a Lian-Li. Dual 120mm radiator fans further reduce noise levels, while 3/8in (10mm) tubing tackles dual CPU, dual/SLI video coolers, and other demanding setups. The PC3-726 features a new Koolance LED display panel, which monitors 3 separate temperature channels- each with it's own configurable alarm setting.

- Radiator fan speeds adjust automatically, or with 10 manual levels
- Blue reservoir LED lighting
- Top refill plug
- Variable safety shutdown temperature
- Easy-latch side door
- Three interior zones to isolate hardware for better heat dissipation
- Front and rear case perforations for improved ambient conditions
- Sliding hard drive tracks for easy installation
- Aluminum rolling casters with brake
- Front USB 2.0 and 1394 Firewire ports
- Includes front and rear 120mm case fans


NOTE: PC3-726 & PC3-736 systems will fit power supplies deeper than 9.5" (24.1cm) if the nearest hard drive bay is removed. This would reduce the 3.5" hard drive capacity by half.

Intended Tubing Size

ID: 10mm (3/8")

OD: 13mm (1/2")

Wall: 1.5mm (1/16")

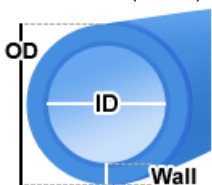

General	
Weight	33.10 lb (15.01 kg)
Cooling Systems	
Display Type	LED
Fans	2 x 120mm (180CFM)
Flow Rate	R-PMP01
Power Source	12 VDC
Radiator	Aluminum
Temperature Sensors	50K Thermistor