



Large dual CPU systems are accommodated by the PC3-726, which provides support for motherboards up to 12" x 13" (30.5cm x 33cm). This model does *not* include a side window.

An ultimate combination of cooling power in aluminum! Koolance's PC3-726 includes the new 700W pro cooling system merged with a Lian-Li. Dual 120mm radiator fans further reduce noise levels, while 3/8in (10mm) tubing tackles dual CPU, dual/SLI video coolers, and other demanding setups. The PC3-726 features a new Koolance LED display panel, which monitors 3 separate temperature channels- each with it's own configurable alarm setting.

- Radiator fan speeds adjust automatically, or with 10 manual levels
- Blue reservoir LED lighting
- Top refill plug
- Variable safety shutdown temperature
- Easy-latch side door
- Three interior zones to isolate hardware for better heat dissipation
- Front and rear case perforations for improved ambient conditions
- Sliding hard drive tracks for easy installation
- Aluminum rolling casters with brake
- Front USB 2.0 and 1394 Firewire ports
- Includes front and rear 120mm case fans


NOTE: PC3-726 & PC3-736 systems will fit power supplies deeper than 9.5" (24.1cm) if the nearest hard drive bay is removed. This would reduce the 3.5" hard drive capacity by half.

**Intended Tubing Size**

**ID:** 10mm (3/8")

**OD:** 13mm (1/2")

**Wall:** 1.5mm (1/16")

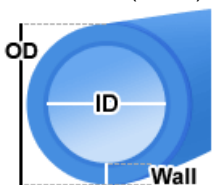

General	
Weight	33.10 lb (15.01 kg)
Cooling Systems	
Display Type	LED
Fans	2 x 120mm (180CFM)
Flow Rate	R-PMP01
Power Source	12 VDC
Radiator	Aluminum
Temperature Sensors	50K Thermistor