



Get the maximum amount of space for large single or dual CPU systems with the PC3-736, which provides support for motherboards up to 12" x 13" (30.5cm x 33cm).

An ultimate combination of cooling power in aluminum! Koolance's PC3-736 includes the new 700W pro cooling system merged with a Lian-Li. Dual 120mm radiator fans further reduce noise levels, while 3/8in (10mm) tubing tackles dual CPU, dual/SLI video coolers, and other demanding setups. The PC3-726 features a new Koolance LED display panel, which monitors 3 separate temperature channels- each with it's own configurable alarm setting.

- Radiator fan speeds adjust automatically, or with 10 manual levels
- Blue reservoir LED lighting
- Top refill plug
- Variable safety shutdown temperature
- Easy-latch side door
- Three interior zones to isolate hardware for better heat dissipation
- Front and rear case perforations for improved ambient conditions
- Sliding hard drive tracks for easy installation
- Aluminum rolling casters with brake
- Front USB 2.0 and 1394 Firewire ports
- Includes front and rear 120mm case fans, with space for two rear 80mm


NOTE: PC3-726 and PC3-736 systems will fit power supplies deeper than 9.5" (24.1cm) if the nearest hard drive bay is removed. This would reduce the 3.5" hard drive capacity by half.

Intended Tubing Size

ID: 10mm (3/8")

OD: 13mm (1/2")

Wall: 1.5mm (1/16")

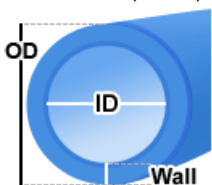

General	
Weight	40.10 lb (18.19 kg)
Cooling Systems	
Display Type	LED
Fans	2 x 120mm (180CFM)
Flow Rate	R-PMP01
Power Source	12 VDC
Radiator	Aluminum
Temperature Sensors	50K Thermistor