

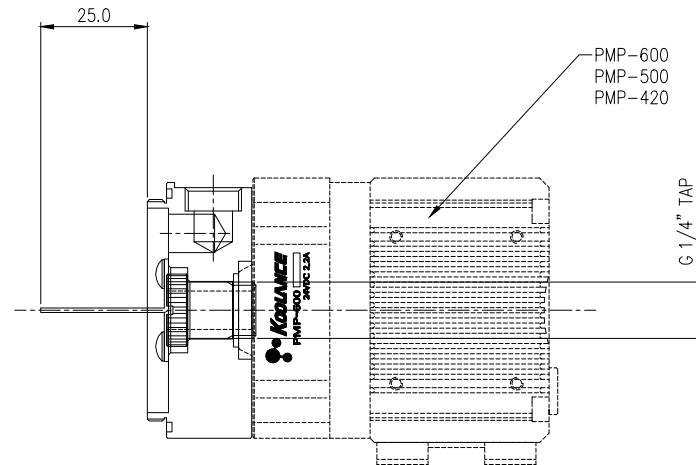


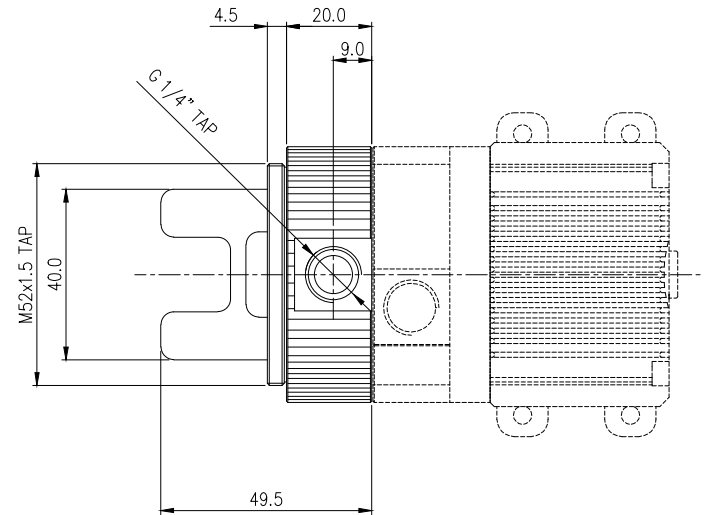


CNT-PMP500T is an acetal reservoir base for the Koolance [PMP-420](#), [PMP-500](#), and [PMP-600](#) (sold separately). Koolance [60mm OD acrylic reservoir bodies](#) can be directly connected to the CNT-PMP500T. The fitting on the reservoir side can be pointed in any direction before tightening to the pump.

O-rings for pump and reservoir sides, a stainless steel liquid partition, and nickel-plated brass attachment fitting are included.

| General | |
|-------------------------------|--|
| Weight | 0.25 lb (0.11 kg) |
| Fitting Thread | G 1/4 BSPP |
| Max Pressure Tolerance @ 25°C | 2kgf/cm2 (28.5psi) |
| Max Temperature Tolerance | 70°C (158°F) |
| Wetted Materials | Nickel-Plated Brass, POM Acetal, Stainless Steel, EPDM |

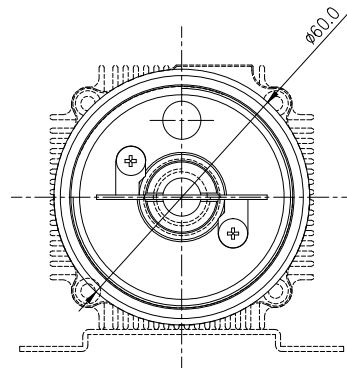

| | | | | | | | | | | |
|---|--|-------------|----|----|----------|-----------|----------------------|------|---------|--|
| | | | | | | | | | | |
| NO. | | DESCRIPTION | | | MATER'L | | QUANTITY | | REMARKS | |
|  | | | | | UNIT | MM | PART NO. CNT-PMP500T | | | |
| | | | | | SCALE | N/S | TITLE Ass'y | | | |
| DATE | | BY | BY | BY | APPRO BY | 3RD ANGLE | | | | |
| DEC.22.2020 | | S.J.LEE | | | | DWG. NO. | | ITEM | | |
| | | | | | | | | | | |