


QD2H Female Quick Disconnect No-Spill Coupling, Panel Barb for 06mm (1/4in)





Koolance patented quick disconnect no-spill coupling with automatic shutoff. 6mm (1/4in) ID female panel-mountable barb fitting with spring clamp for 10mm (3/8in) OD. It will only fit a Koolance QD2H male quick disconnect.

After pulling the ring on the female QDC side, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 10kgf/cm² (142psi).

General	
Weight	0.13 lb (0.06 kg)
Max No-Spill Pressure	10kgf/cm ² (142psi)
Max Pressure Tolerance @ 25° C	12kgf/cm ² (170.7psi)
Max Temperature Tolerance	80° C (176° F)
Min Pressure Tolerance @ 25° C	-1.0kgf/cm ² (-14psi)
Min Storage Temperature (*No Freezing)	-20° C (-4° F)
Seal Material	EPDM (Water/Glycol Liquids)
Wetted Materials	Nickel-Plated Brass, Stainless Steel, EPDM

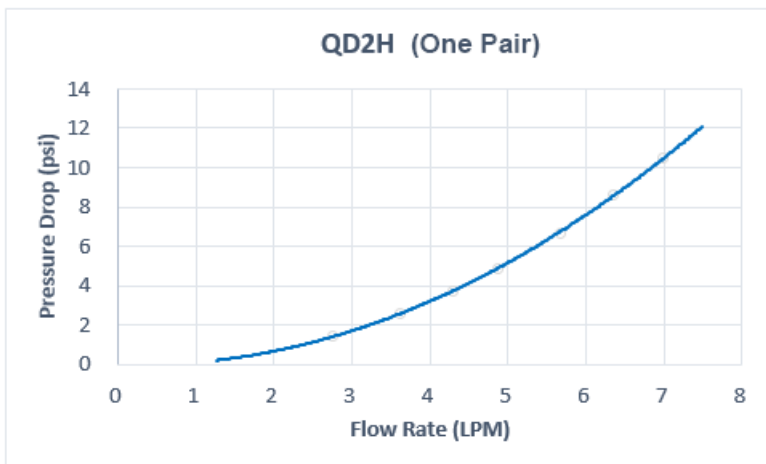

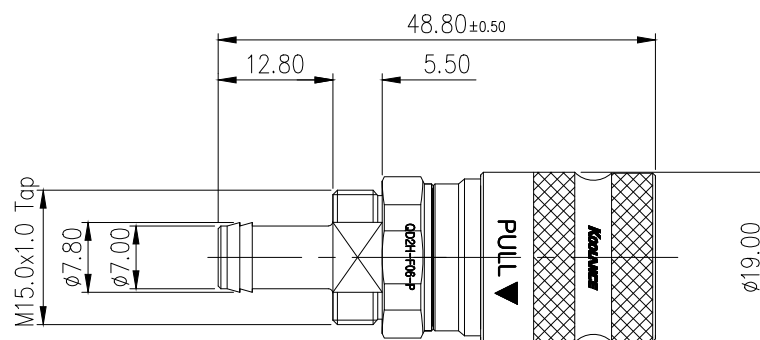

NO.		DESCRIPTION			MATER'L		QUANTITY		REMARKS	
 KOOLANCE®					UNIT	MM	PART NO. QD2H-F06-P			
					SCALE	N/S	TITLE			
DATE		BY	BY	BY	APPRO	BY	DIMENSION			
		song					DWG. NO.		ITEM	
									QD2H	