


**QD2H Female Quick Disconnect No-Spill  
Coupling, Panel Barb for 06mm (1/4in)**




Koolance patented quick disconnect no-spill coupling with automatic shutoff. 6mm (1/4in) ID female panel-mountable hose barb with clamp for 10mm (3/8in) OD. It will only fit a Koolance QD2H male quick disconnect.


After pulling the ring on the female QDC side, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 10kgf/cm2 (142psi).

General	
Weight	0.13 lb (0.06 kg)
Max No-Spill Pressure	10kgf/cm2 (142psi)
Max Pressure Tolerance @ 25° C	12kgf/cm2 (170.7psi)
Max Temperature Tolerance	80° C (176° F)
Min Pressure Tolerance @ 25° C	-1.0kgf/cm2 (-14psi)
Min Storage Temperature (*No Freezing)	-20°C (-4°F)
Seal Material	EPDM (Water/Glycol Liquids)
Wetted Materials	Nickel-Plated Brass, Stainless Steel, EPDM

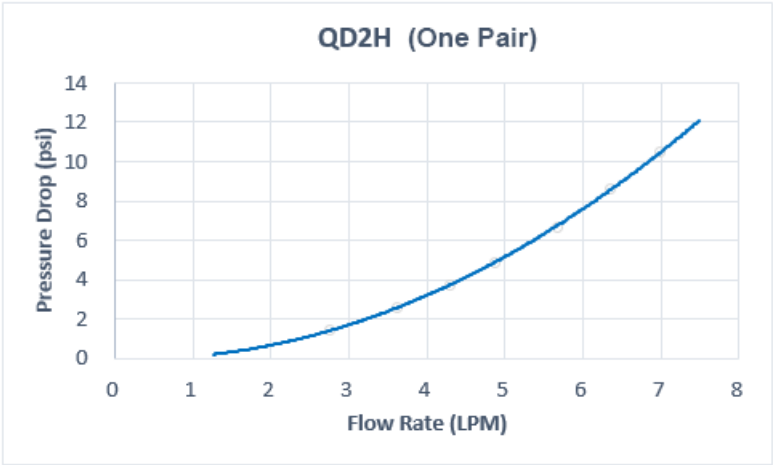

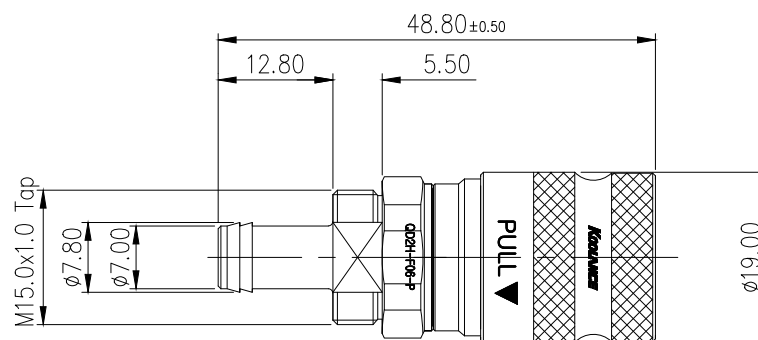

NUT DIMENSION

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
 <b>KOOLANCE®</b>					UNIT	MM	PART NO. QD2H-F06-P	
					SCALE	N/S	TITLE	
DATE		BY	BY	BY	APPRO	BY	DIMENSION	
		song					DWG. NO.	
							ITEM	
							QD2H	