


**QD3 Male Quick Disconnect No-Spill Coupling,
Barb for ID 10mm (3/8in)**




Koolance patented quick disconnect no-spill coupling with automatic shutoff. 10mm (3/8in) ID male hose barb with clamp for 13mm (1/2in) OD. It will only fit a Koolance QD3 female quick disconnect.

After pulling the ring on the female QDC side, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm² (7psi).

General	
Weight	0.13 lb (0.06 kg)
Materials	Brass, Nickel Plating, Stainless Steel, EPDM
Max Pressure Tolerance @ 25° C	8kgf/cm ² (113.8psi)
Max Temp. Operating Tolerance	100° C (212° F)

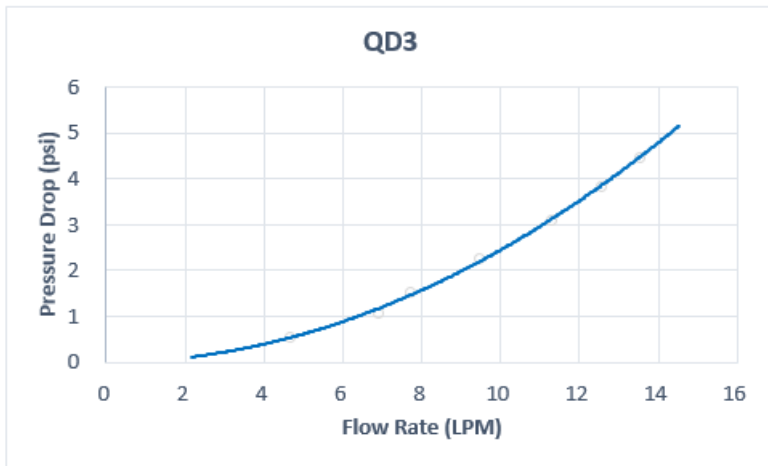

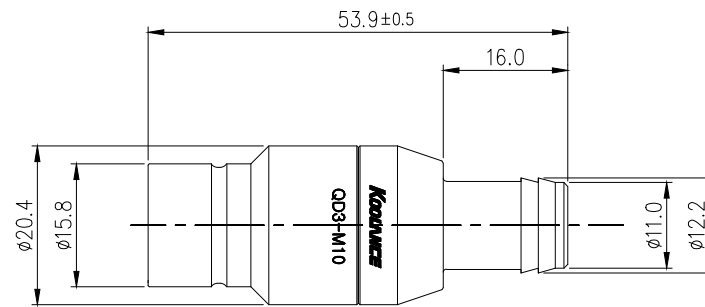

REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY

REVISION

NO.	DISCRIPTION			MATER'L		QUANTITY	REMARKS
				UNIT	MM	ITEM	QD3
				SCALE	N/S	TITLE	QD3-M10
						3RD ANGLE	
						CODE NO.	DWG. NO.
							PAGE

DECIMAL PLACES	INCHES	MILLIMETRES
.XXX	±.005	±0.1
.XX	±.010	±0.3
.X	±.020	±0.5

XX'	±0.5'
XX.X'	±0.1'

SURFACE ROUGHNESS	SURFACE	SURFACE
	.63	1.6