


**QD3H Female Quick Disconnect No-Spill Coupling, Panel Barb for ID 13mm (1/2in)**






Koolance patented quick disconnect no-spill coupling with automatic shutoff. 13mm (1/2in) ID female panel-mountable hose barb with clamp for 16mm OD (5/8in). It will only fit a Koolance QD3H male quick disconnect.

After pulling the ring on the female QDC side, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 10kgf/cm<sup>2</sup> (142psi).

General	
Weight	0.21 lb (0.10 kg)
Materials	Brass, Nickel Plating, Stainless Steel, EPDM
Max Pressure Tolerance @ 25° C	12kgf/cm <sup>2</sup> (170.7psi)
Max Temp. Operating Tolerance	100° C (212° F)

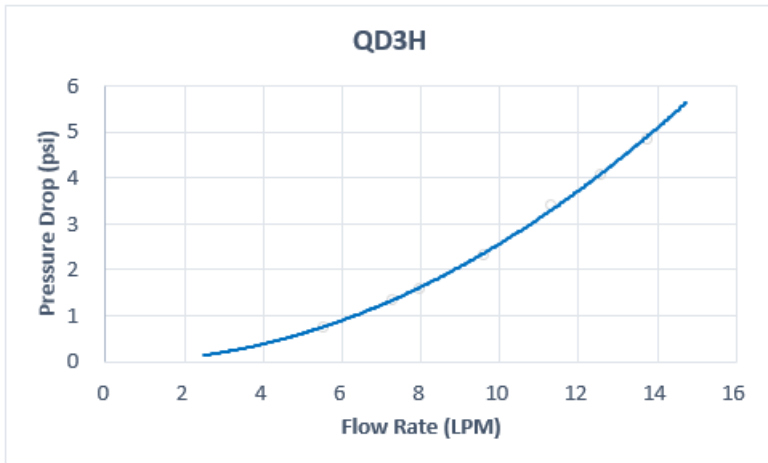

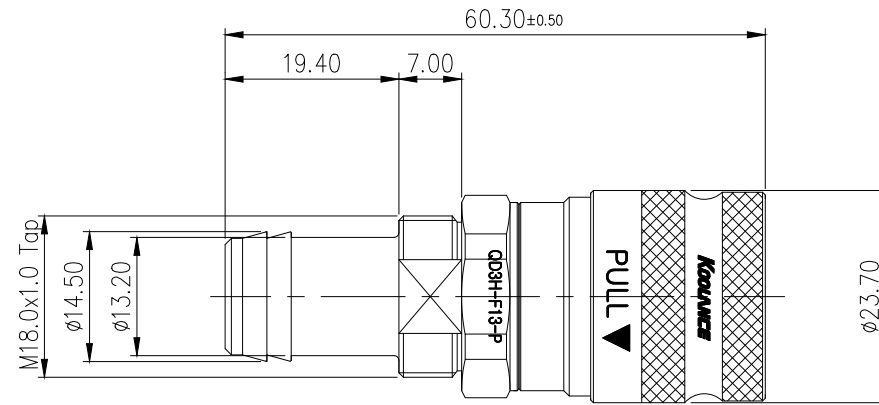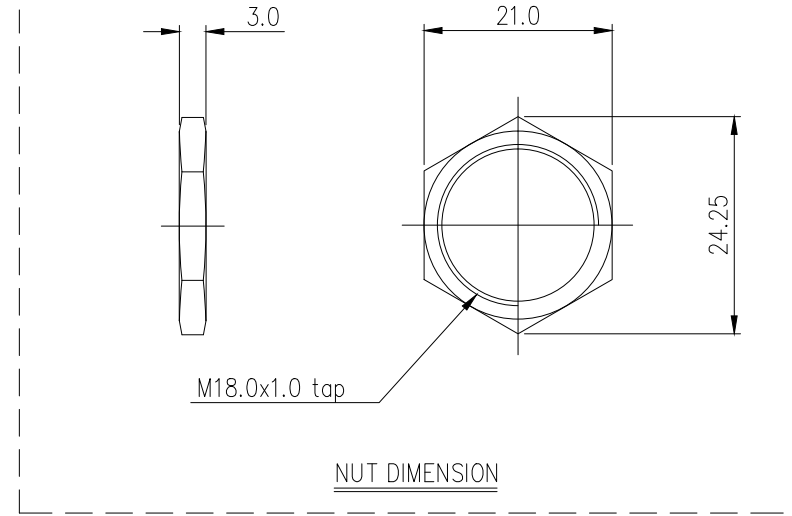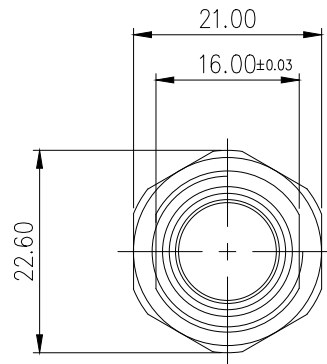

REV	DATE	CONTENTS	APPD BY
REVISION			

NO.	DESCRIPTION			MATER'L	QUANTITY	REMARKS
		UNIT	MM	PART NO. QD3H-F13-P		
DATE	BY	BY	BY	APPRD BY	TITLE	
song					DIMENSION	
					DWG. NO.	ITEM
						QD3H