


QD3H Female Quick Disconnect No-Spill Coupling, Male Threaded G 1/4 BSPP




Koolance patented quick disconnect no-spill coupling with automatic shutoff. G 1/4 BSPP (parallel) thread female fitting for screwing directly into a water block or other component. It will only fit a Koolance QD3H male quick disconnect.


After pulling the ring on the female QDC side, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 10kgf/cm² (142psi).

General	
Weight	0.17 lb (0.08 kg)
Fitting Thread	G 1/4 BSPP
Max No-Spill Pressure	10kgf/cm ² (142psi)
Max Pressure Tolerance @ 25° C	12kgf/cm ² (170.7psi)
Max Temperature Tolerance	80° C (176° F)
Min Pressure Tolerance @ 25° C	0.0kgf/cm ² (0psi)
Min Storage Temperature (*No Freezing)	-20° C (-4° F)
Seal Material	EPDM (Water/Glycol Liquids)
Wetted Materials	Brass, Nickel Plating, Stainless Steel, EPDM

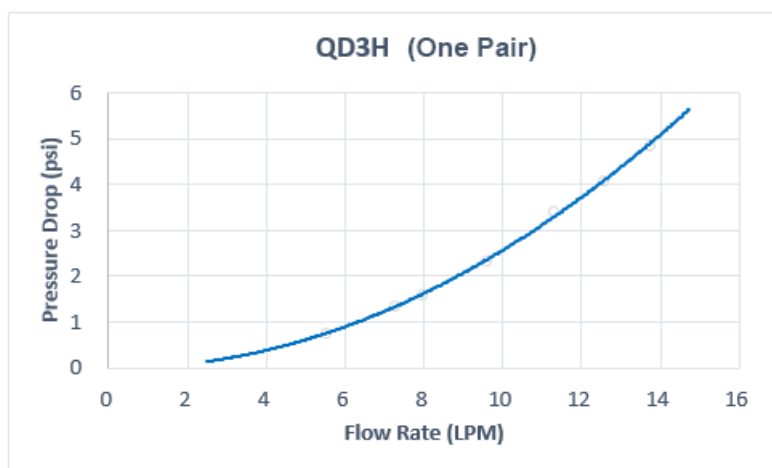

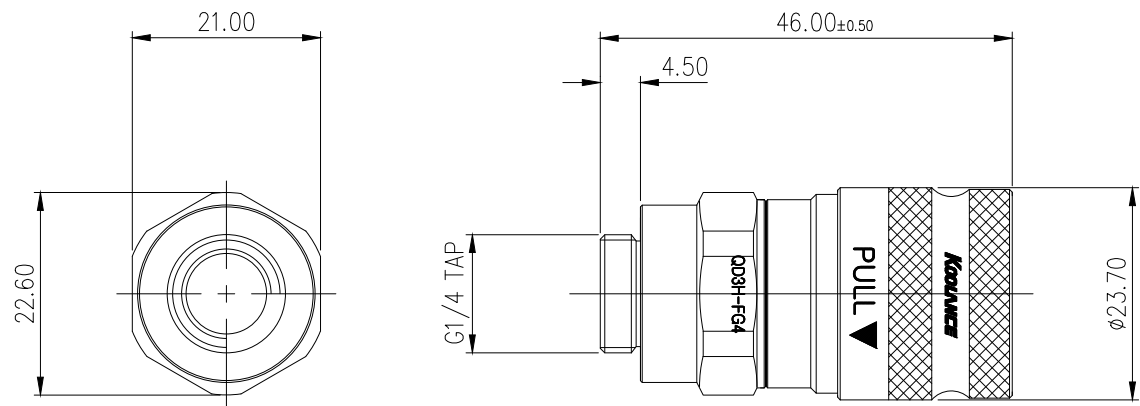

REV	DATE	CONTENTS	APPD BY
REVISION			

	DESCRIPTION		MATER'L	QUANTITY	REMARKS
NO.			UNIT	MM	PART NO. QD3H-FG4
			SCALE	N/S	TITLE
	BY	BY	BY	APPRD BY	DIMENSION
DATE					
	song				ITEM
					QD3H