
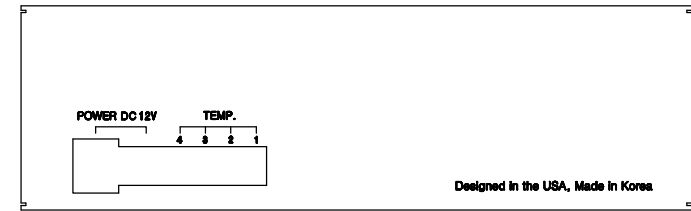



**Temperature Sensor Display for Four 10K-
Ohm Thermistors**

Temperature sensor display for up to four Koolance 10K-Ohm thermistors (sensors not included). The display can be toggled between °C and °F units by holding the button for one second. A 4-pin Molex connector is provided for input power, or alternatively, the display accepts a 12VDC 5.5mm barrel plug (not included). The maximum readable temperature range is -30°C to 90°C (-22°F to 194°F).

General	
Weight	0.40 lb (0.18 kg)

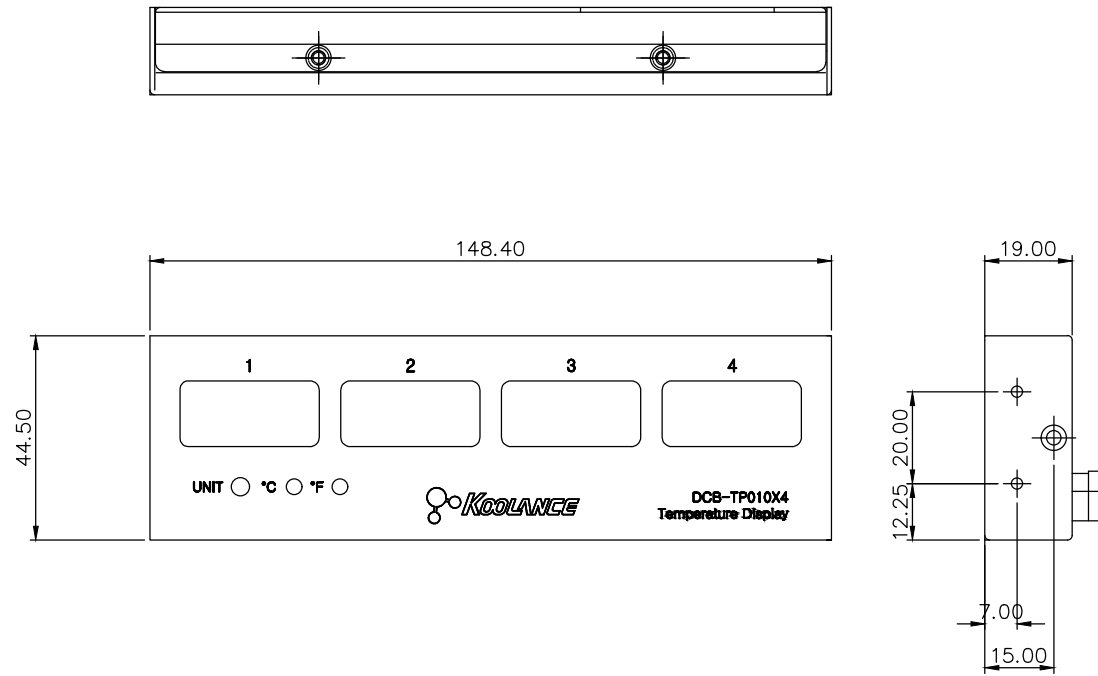

△			
REV	DATE	CONTENTS	APPD BY
REVISION			

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS
						UNIT	MM	PART NO. DCB-TP010X4	
						SCALE	N/S	TITLE	
	BY	BY	BY	APPRO	BY	3RD ANGLE		Ass'y	
DATE									
12.29.2021	YS.SHIN					DWG. NO.		ITEM	