



www.koolance.com

Specifications Sheet

Generated: 2024-05-10




 
P/N: DCB-TP010X4


Temperature Sensor Display for Four 10K-Ohm Thermistors



Temperature sensor display for up to four Koolance 10K-Ohm thermistors (sensors not included). The display can be toggled between °C and °F units by holding the button for one second. A 4-pin Molex connector is provided for input power, or alternatively, the display accepts a 12VDC 5.5mm barrel plug (not included). The maximum readable temperature range is -30°C to 90°C (-22°F to 194°F).

General	
Weight	0.40 lb (0.18 kg)

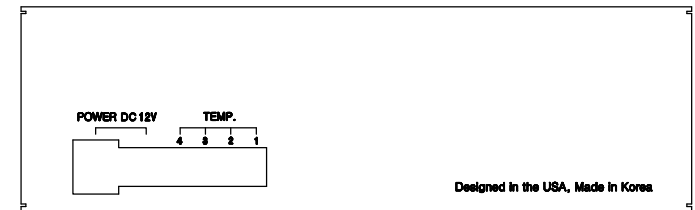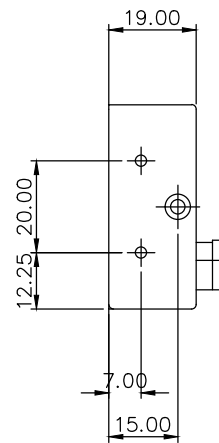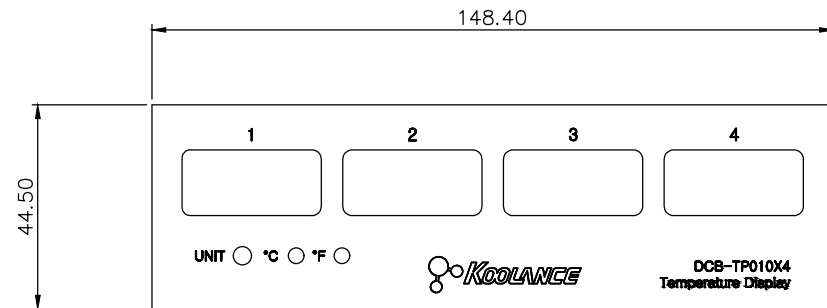

NO.	DESCRIPTION				MATER'L		QUANTITY		REMARKS	
 KOOLANCE®					UNIT	MM	PART NO. DCB-TP010X4			
					SCALE	N/S	TITLE Ass'y			
	BY	BY	BY	APPRD BY	3RD ANGLE					
DATE					DWG. NO.		ITEM			
12.29.2021	YS.SHIN									

[illegible]