


**QDT2 Viton Female Quick Disconnect No-Spill  
Coupling, Compression for 06mm x 10mm  
(1/4in x 3/8in)**




Koolance patented quick disconnect no-spill coupling with automatic shutoff. 6mm (1/4in) ID female straight connection with compression fitting. It will only fit a Koolance QDT2 male quick disconnect.


After pulling the ring on the female QDC side, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed.

General	
Weight	0.13 lb (0.06 kg)
Max No-Spill Pressure	10kgf/cm2 (142psi)
Max Pressure Tolerance @ 25° C	12kgf/cm2 (170.7psi)
Max Temperature Tolerance	80° C (176° F)
Min Pressure Tolerance @ 25° C	-1.0kgf/cm2 (-14psi)
Min Storage Temperature (*No Freezing)	-40°C (-40°F) Connected, -30°C (-22°F) Disconnected
Seal Material	Viton (Oil Liquids)
Wetted Materials	Chrome-Plated Brass, Stainless Steel, Viton

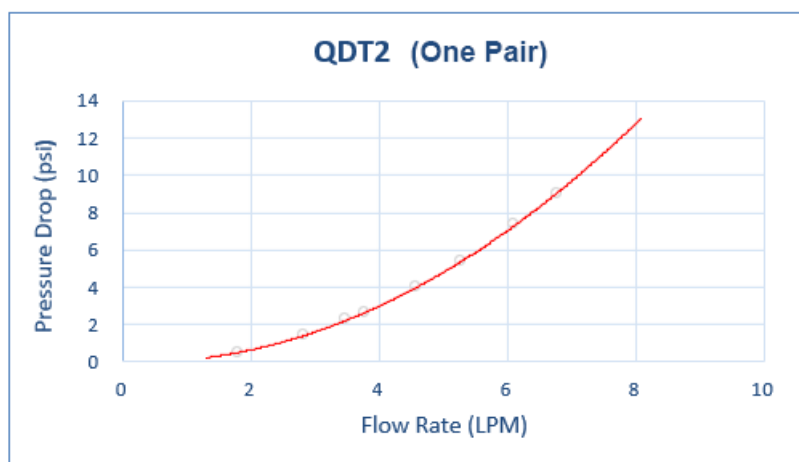

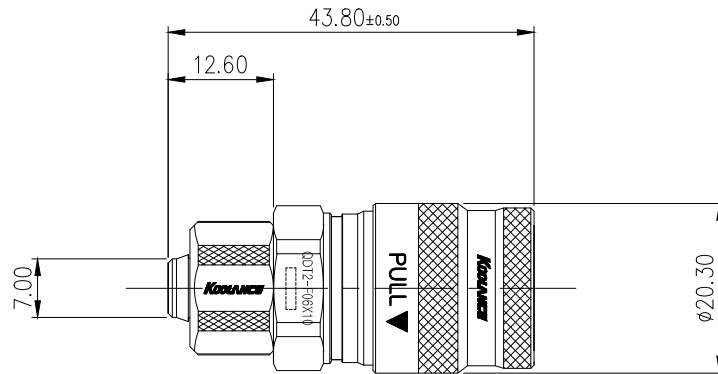

REV	DATE	CONTENTS	APPD BY
REVISION			

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
 <b>KOOLANCE®</b>					UNIT	MM	PART NO. QDT2-F06X10	
					SCALE	N/S	TITLE  DIMENSION	
DATE	BY	BY	BY	APPRO BY	3RD ANGLE			
	S.J.LEE							