


QD4 Male Quick Disconnect No-Spill Coupling, Compression for 13mm x 19mm (1/2in x 3/4in)






Koolance patented quick disconnect no-spill coupling with automatic shutoff. 13mm (1/2in) ID, 19mm (3/4in) OD male straight connection with compression fitting. It will only fit a Koolance QD4 female quick disconnect.

After pulling the ring on the female QDC side, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm² (7psi).

| General | |
|--|--|
| Weight | 0.28 lb (0.13 kg) |
| Max No-Spill Pressure | 0.5kgf/cm ² (7psi) |
| Max Pressure Tolerance @ 25° C | 8kgf/cm ² (113.8psi) |
| Max Temperature Tolerance | 80° C (176° F) |
| Min Pressure Tolerance @ 25° C | -1.0kgf/cm ² (-14psi) |
| Min Storage Temperature (*No Freezing) | -20° C (-4° F) |
| Seal Material | EPDM (Water/Glycol Liquids) |
| Wetted Materials | Brass, Nickel Plating, Stainless Steel, EPDM |

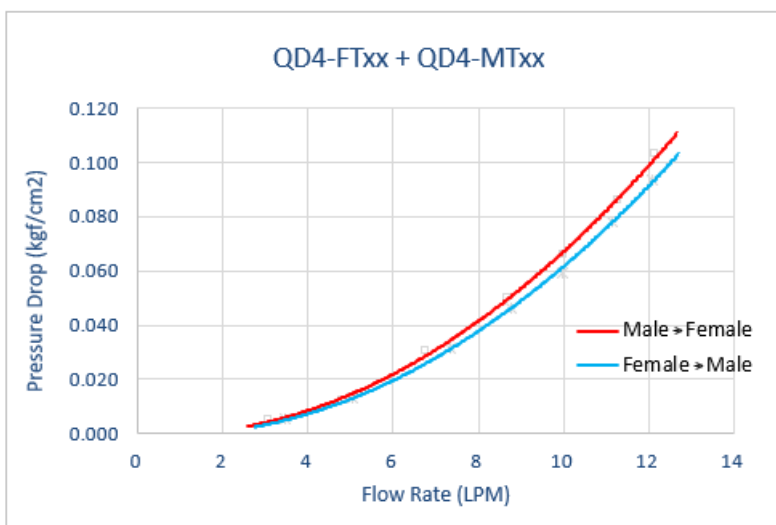

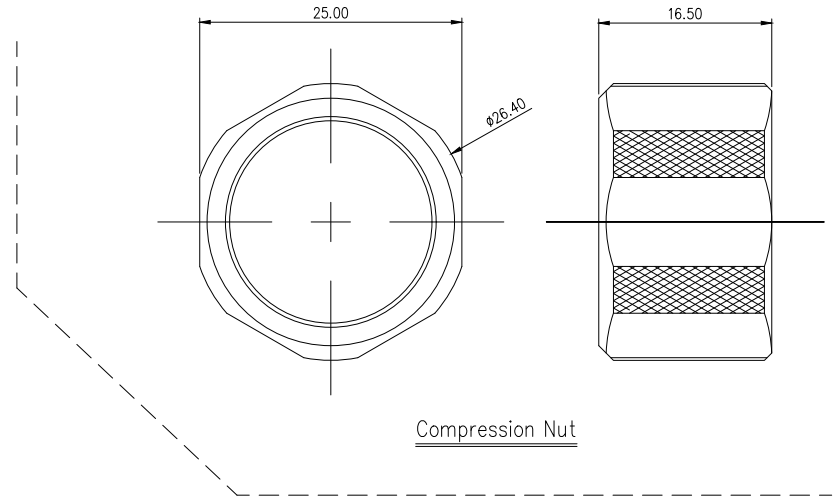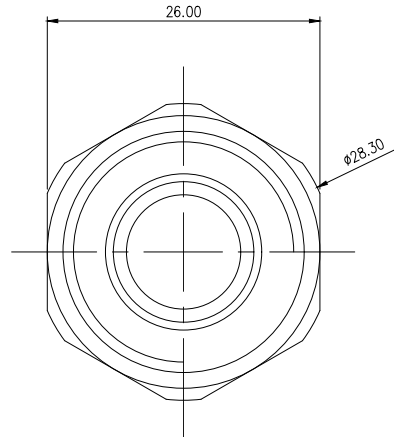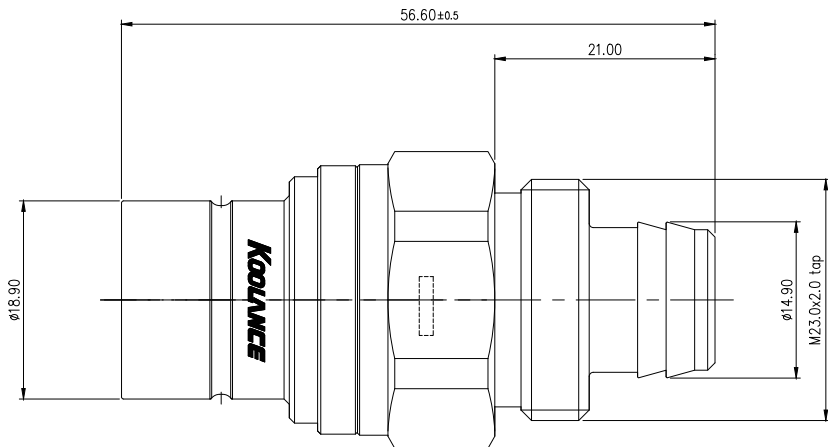

| REV | DATE | CONTENTS | REVD BY | CHKD BY | APPD BY |
|----------|------|----------|---------|---------|---------|
| REVISION | | | | | |

| NO. | DESCRIPTION | | | | MATER'L | QUANTITY | REMARKS |
|-----------|-------------|----|----|----------|-----------|--------------------|----------|
| | | | | | UNIT | MM | PART NO. |
| | BY | BY | BY | APPRO BY | SCALE | N/S | TITLE |
| DATE | | | | | 3RD ANGLE | | |
| 2025.7.31 | SONG | | | | DWG. NO. | ITEM | REV. |
| | | | | | | QD4 Press-fit Type | |