




Koolance acrylic reservoir body for combining with various top and bottom attachments. Please select the "Add" options above for convenient combinations.

Model	Diameter	Height	Capacity (Approx.)
BDY-TK030	60mm (2.36")	30mm (1.2")	59ml (2.0 fl oz)
BDY-TK050	60mm (2.36")	50mm (2.0")	98ml (3.3 fl oz)
BDY-TK080	60mm (2.36")	80mm (3.15")	157ml (5.3 fl oz)
BDY-TK120	60mm (2.36")	120mm (4.72")	236ml (7.9 fl oz)
BDY-TK200	60mm (2.36")	200mm (7.87")	393ml (13.3 fl oz)
BDY-TK240	60mm (2.36")	240mm (9.45")	471ml (15.9 fl oz)

General	
Weight	0.50 lb (0.23 kg)
Max Pressure @ 25°C	2kgf/cm2 (28.5psi)
Max Temperature	80°C (176°F)
Reservoirs	
Capacity	393ml (13.3 fl oz)

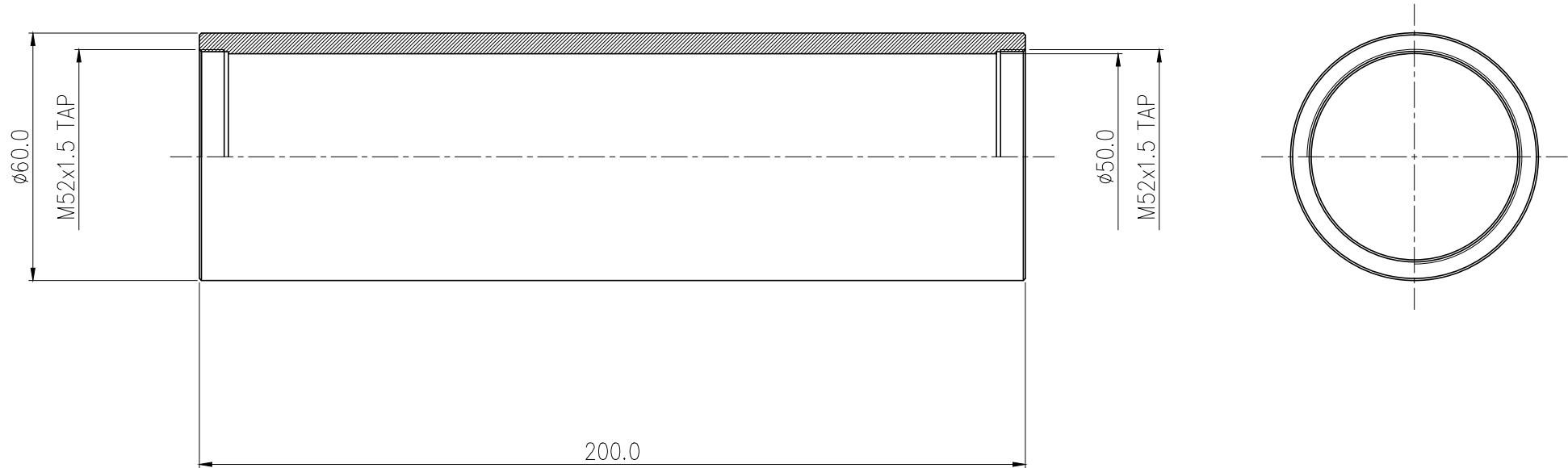

NO.	DESCRIPTION	MATER'L		QUANTITY	REMARKS
	KOOLANCE	UNIT	MM	APPAR	BDY-TK200
		SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRO BY	Ass'y
04/07/2017	S.J.LEE				
					3RD ANGLE
					CODE NO.
					DWG. NO.