



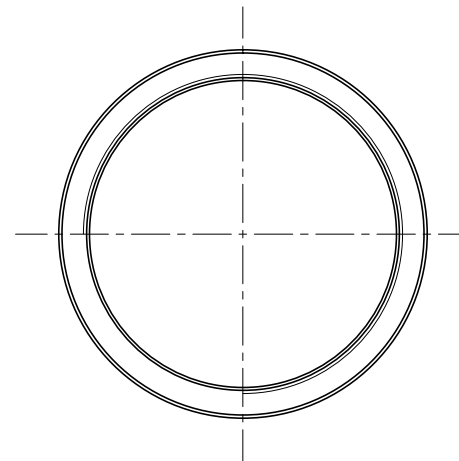

Koolance acrylic reservoir body for combining with various top and bottom attachments. Please select the "Add" options above for convenient combinations.

Model	Diameter	Height	Capacity (Approx.)
<a href="#">BDY-TK030</a>	60mm (2.36")	30mm (1.2")	59ml (2.0 fl oz)
<a href="#">BDY-TK050</a>	60mm (2.36")	50mm (2.0")	98ml (3.3 fl oz)
<a href="#">BDY-TK080</a>	60mm (2.36")	80mm (3.15")	157ml (5.3 fl oz)
<a href="#">BDY-TK120</a>	60mm (2.36")	120mm (4.72")	236ml (7.9 fl oz)
<a href="#">BDY-TK200</a>	60mm (2.36")	200mm (7.87")	393ml (13.3 fl oz)

General	
Weight	0.12 lb (0.05 kg)
Max Pressure Tolerance @ 25° C	2kgf/cm2 (28.5psi)
Max Temperature Tolerance	80° C (176° F)
Reservoirs	
Capacity	59ml (2.0 fl oz)

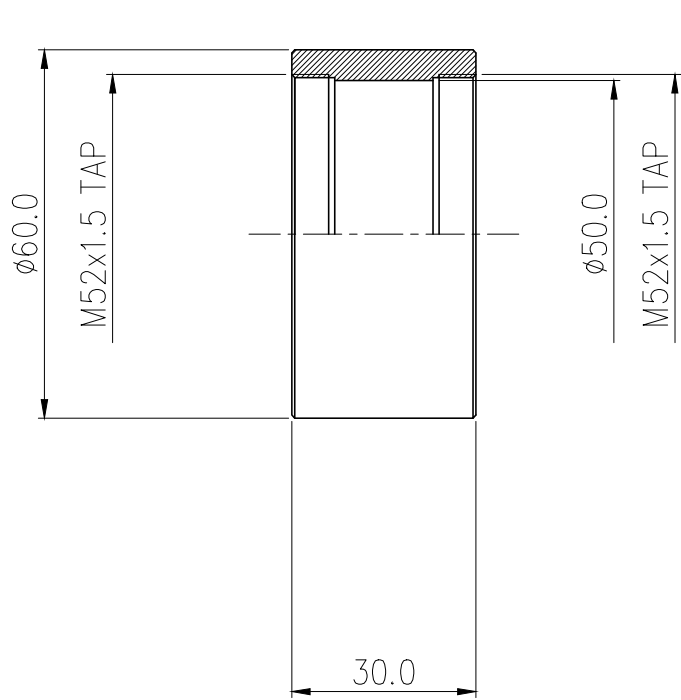

NO.	DESCRIPTION	MATER'L		QUANTITY	REMARKS
	<b>KOOLANCE</b>	UNIT	MM	APPAR	BDY-TK030
		SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRO BY	Ass'y
04/07/2017	S.J.LEE				
					3RD ANGLE
					CODE NO.
					DWG. NO.