



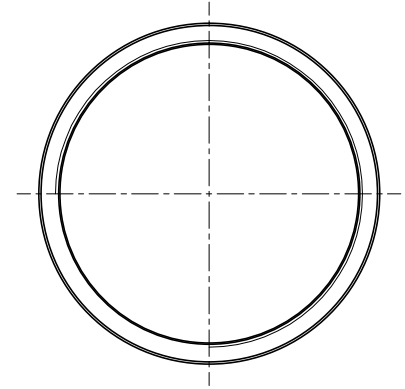


Koolance acrylic reservoir body for combining with various top and bottom attachments. Please select the "Add" options above for convenient combinations.

Model	Diameter	Height	Capacity (Approx.)
BDY-TK050X70	80mm (3.15")	50mm (2.0")	192ml (6.5 fl oz)
BDY-TK080X70	80mm (3.15")	80mm (3.15")	308ml (10.4 fl oz)
BDY-TK120X70	80mm (3.15")	120mm (4.72")	462ml (15.6 fl oz)
BDY-TK200X70	80mm (3.15")	200mm (7.87")	770ml (26.0 fl oz)
BDY-TK240X70	80mm (3.15")	240mm (9.45")	924ml (31.2 fl oz)

General	
Weight	1.00 lb (0.45 kg)
Max Pressure @ 25°C	2kgf/cm ² (28.5psi)
Max Temperature	80°C (176°F)
Reservoirs	
Capacity	924ml (31.2 fl oz)

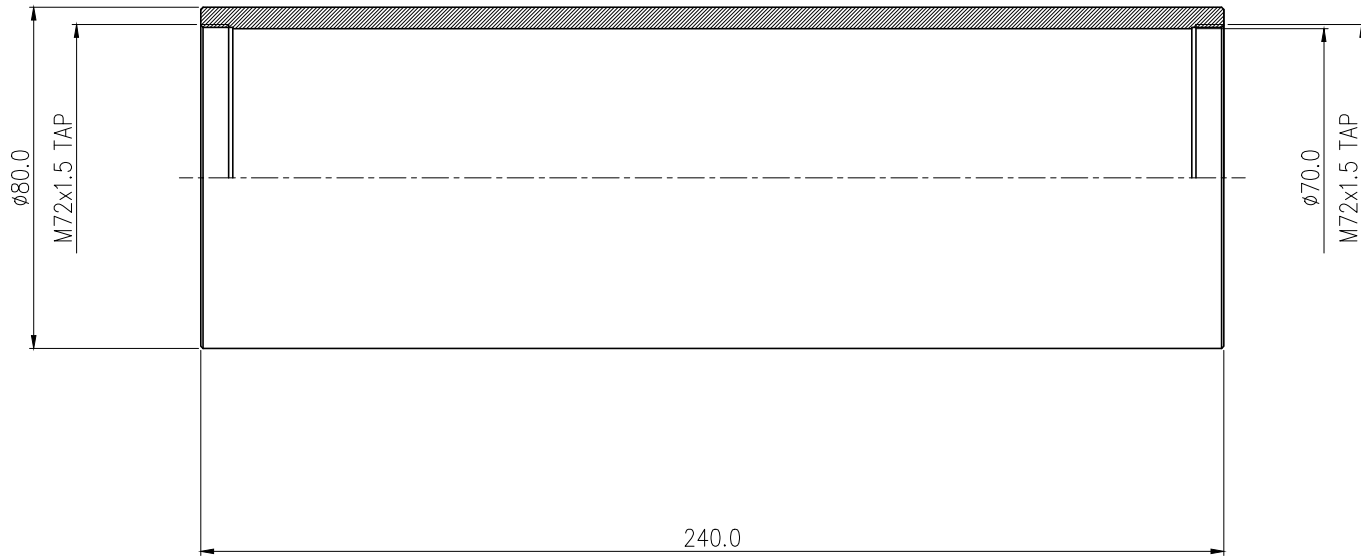

NO.	DESCRIPTION	MATER'L		QUANTITY	REMARKS
		UNIT	MM	APPAR	BDY-TK240X70
		SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRO BY	Ass'y
04/07/2017	S.J.LEE				
					3RD ANGLE
					CODE NO.
					DWG. NO.