



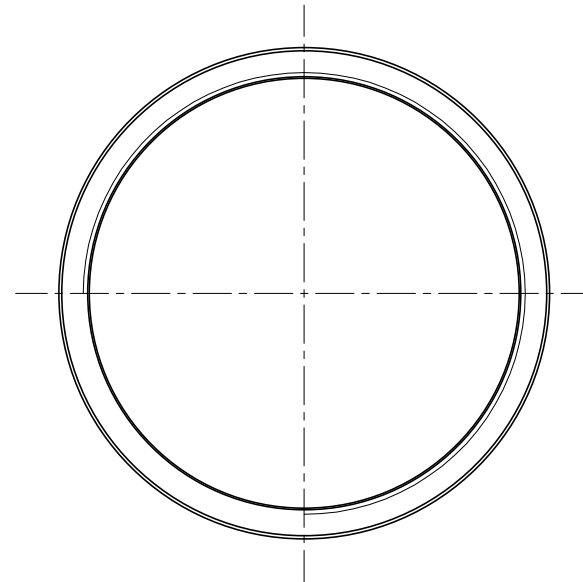


Koolance acrylic reservoir body for combining with various top and bottom attachments. Please select the "Add" options above for convenient combinations.

Model	Diameter	Height	Capacity (Approx.)
<a href="#">BDY-TK050X70</a>	80mm (3.15")	50mm (2.0")	192ml (6.5 fl oz)
<a href="#">BDY-TK080X70</a>	80mm (3.15")	80mm (3.15")	308ml (10.4 fl oz)
<a href="#">BDY-TK120X70</a>	80mm (3.15")	120mm (4.72")	462ml (15.6 fl oz)
<a href="#">BDY-TK200X70</a>	80mm (3.15")	200mm (7.87")	770ml (26.0 fl oz)
<a href="#">BDY-TK240X70</a>	80mm (3.15")	240mm (9.45")	924ml (31.2 fl oz)

General	
Weight	0.25 lb (0.11 kg)
Max Pressure Tolerance @ 25 °C	2kgf/cm2 (28.5psi)
Max Temp. Operating Tolerance	80 °C (176 °F)
Reservoirs	
Capacity	192ml (6.5 fl oz)

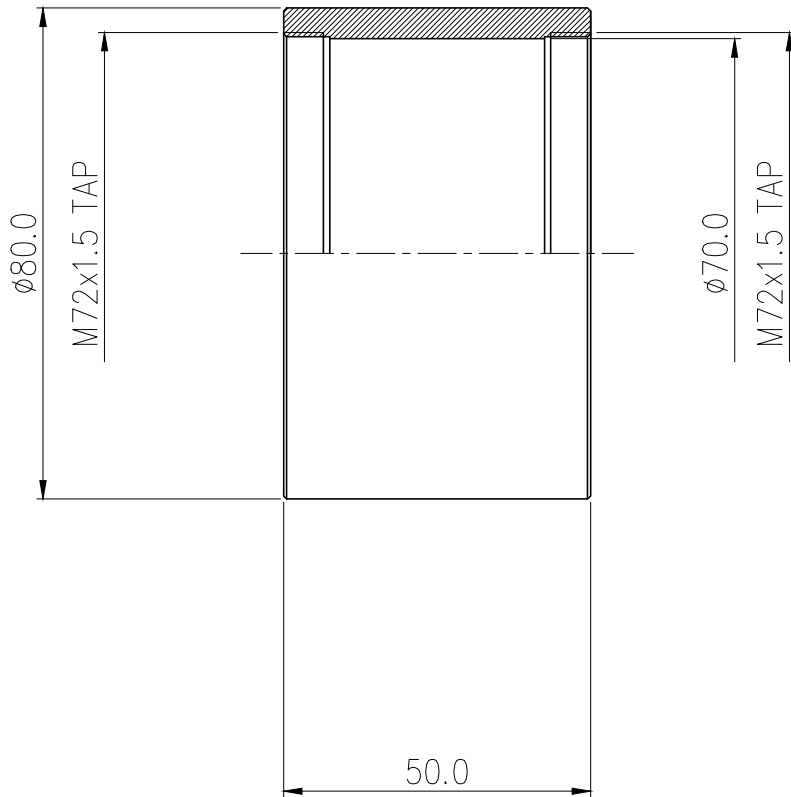

NO.	DESCRIPTION	MATER'L		QUANTITY	REMARKS
		UNIT	MM	APPAR	BDY-TK050X70
		SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRO BY	Ass'y
04/07/2017	S.J.LEE				
					3RD ANGLE
					CODE NO.
					DWG. NO.