

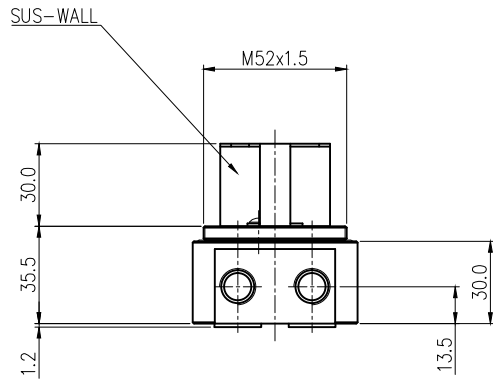
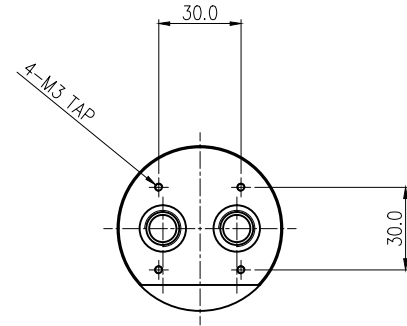


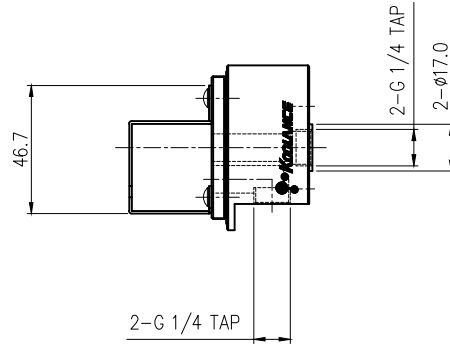

Acetal fitting base for Koolance [60mm OD reservoir bodies](#). Redundant inlet and outlets are provided for inline or parallel loops. Two nickel-plated brass socket plugs, a reservoir o-ring, and removable stainless steel partition are included.

General	
Weight	0.30 lb (0.14 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25°C	2kgf/cm ² (28.5psi)
Max Temp. Operating Tolerance	80°C (176°F)

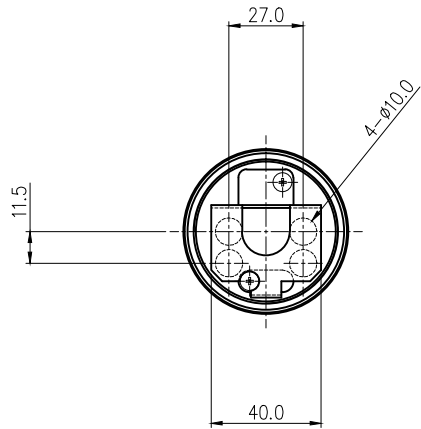

REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY

NO.	DESCRIPTION	MATER'L	QUANTITY	REMARKS
KODANCE		UNIT	MM	APPAR COV-TKBTM
		SCALE	N/S	TITLE
DATE	BY	BY	BY	3RD ANGLE
	S.J.LEE			REF. NO.
				DWG. NO.

REVISION