

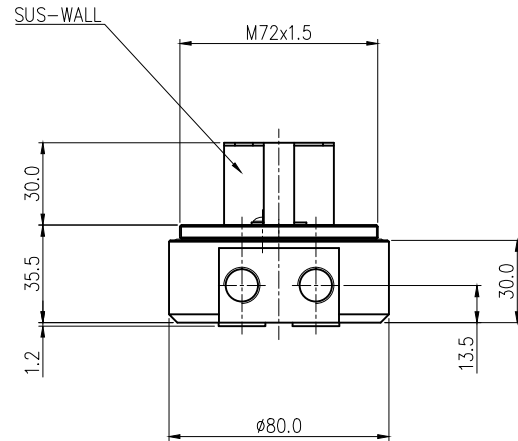
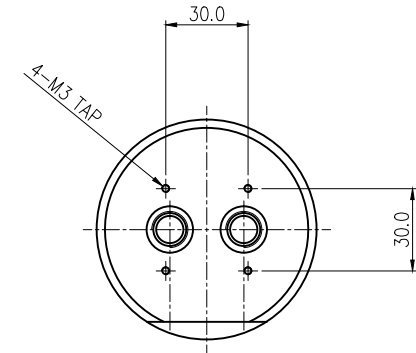


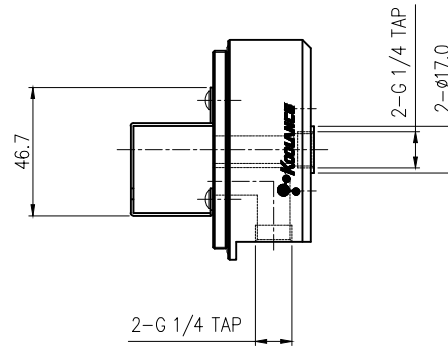

Acetal fitting base for Koolance [80mm OD reservoir bodies](#). Redundant inlet and outlets are provided for inline or parallel loops. Two nickel-plated brass socket plugs, a reservoir o-ring, and removable stainless steel partition are included.

| General | |
|----------------------|--------------------------------|
| Weight | 0.65 lb (0.29 kg) |
| Fitting Thread | G 1/4 BSPP |
| Max Pressure @ 25 °C | 2kgf/cm ² (28.5psi) |
| Max Temperature | 80 °C (176 °F) |

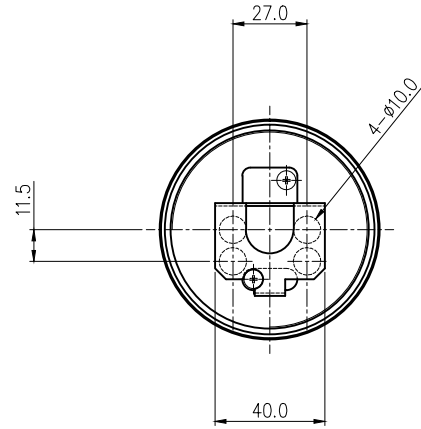

| NO. | DESCRIPTION | MATER'L | | QUANTITY | REMARKS |
|--------------------------------|-------------|---------|----------|----------|------------------------|
| KOLANCE _{INC.} | | UNIT | MM | APPAR | COV-TKBTMX70 |
| | | SCALE | N/S | TITLE | |
| | BY | BY | BY | APPRO BY | SUS-wall version Ass'y |
| DATE | 3RD ANGLE | | | | |
| S.J.LEE | | | REF. NO. | DWG. NO. | |

| REV | DATE | CONTENTS | REVD BY | CHKD BY | APPD BY |
|----------|------|----------|---------|---------|---------|
| | | | | | |
| REVISION | | | | | |