



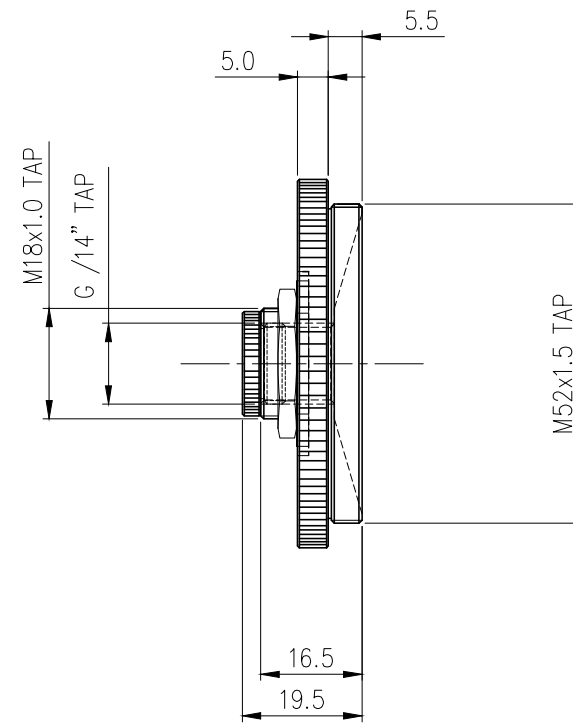


Acetal reservoir top for Koolance [60mm OD reservoir bodies](#). Nickel-plated brass, G 1/4 BSPP (parallel) thread top fill port. Hex mounting nut and insulating washer included.

General	
Weight	0.10 lb (0.05 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	2kgf/cm2 (28.5psi)
Max Temperature Tolerance	80° C (176° F)

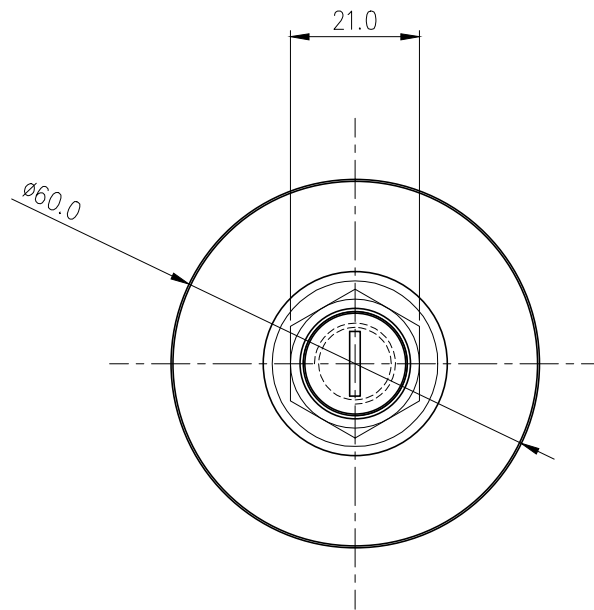

NO.		DESCRIPTION			MATER'L		QUANTITY	REMARKS
					UNIT	MM	APPAR COV-TKTOP	
					SCALE	N/S	TITLE	
DATE		BY	BY	BY	APPRO BY	Ass'y		
04/10/2017		S.J.LEE				CODE NO.		DWG. NO.