







The RP-985 incorporates Koolance's [PMP-300](#) pump. Designed to fit a single 5.25" (CD) bay, it utilizes the same reservoir, front LED display, and rear G 1/4 BSPP (parallel) thread fitting sockets.

Features:

- Fits a single 5.25" CD bay
- Adjusts radiator fan speeds automatically, or with 10 manual levels
- Manual pump speed adjustment
- Variable temperature alarms on 3 independent sensors
- Auto-cycle or static display of all connected temperature sensors
- Variable safety shutdown temperature
- Front and top reservoir blue LED lighting
- Top refill plug

IMPORTANT NOTE: The pump should never be run dry. Always test this product with coolant.

General	
Weight	2.20 lb (1.00 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25°C	1kgf/cm2 (14.2psi)
Max Temperature Tolerance	60°C (140°F)
Reservoirs	
Capacity	237mL (8 fl oz)
Display Type	LED
Pump	PMP-300 @ 12V
Temperature Sensors	10K Thermistors

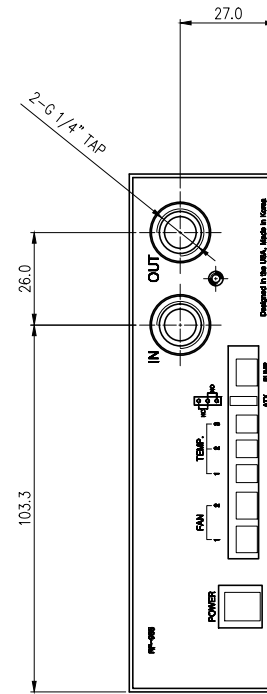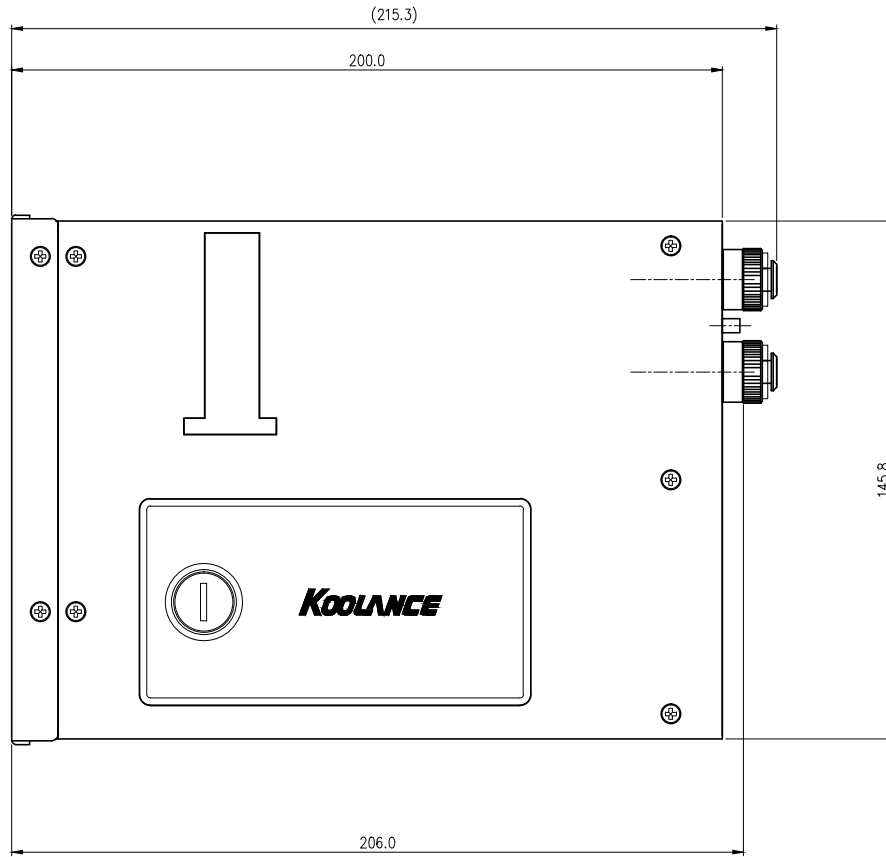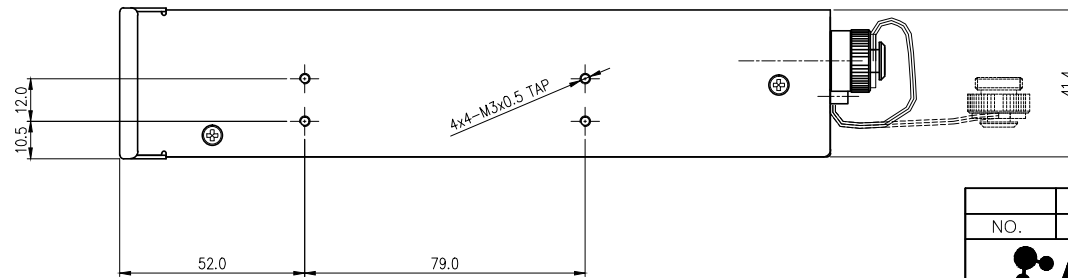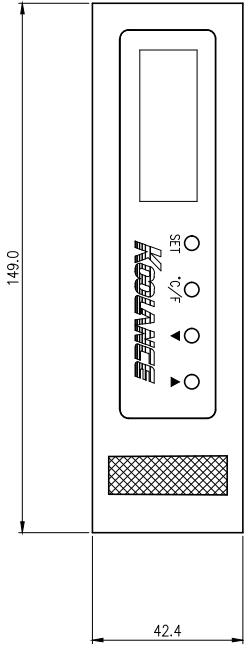

NO.	DESCRIPTION	MATER'L		QUANTITY	REMARKS
	KOOLNCE	UNIT	MM	PART NO.	RP-985
		SCALE	N/S	TITLE	Ass'y
DATE	BY	BY	APPRO BY	3RD ANGLE	
05/02/2017	S.J.LEE			DWG. NO.	ITEM