


Coolant Temperature Sensor, Brass, 10K Ohm



Coolant thermistor temperature sensor with fitting body. This product is designed to be placed inline on any hose. Simply choose G 1/4 BSPP threaded fittings for the desired hose diameter. Wire length = 30" (76cm). Construction is nickel-plated brass. NOTE: This sensor will only work with Koolance products which use 10K Ohm @25°C sensors (first introduced in 2011).

General	
Weight	0.21 lb (0.10 kg)
Fitting Thread	G 1/4 BSPP
Materials	Nickel-Plated Brass, Stainless Steel, EPDM
Max Temp. Operating Tolerance	120° C (248° F)

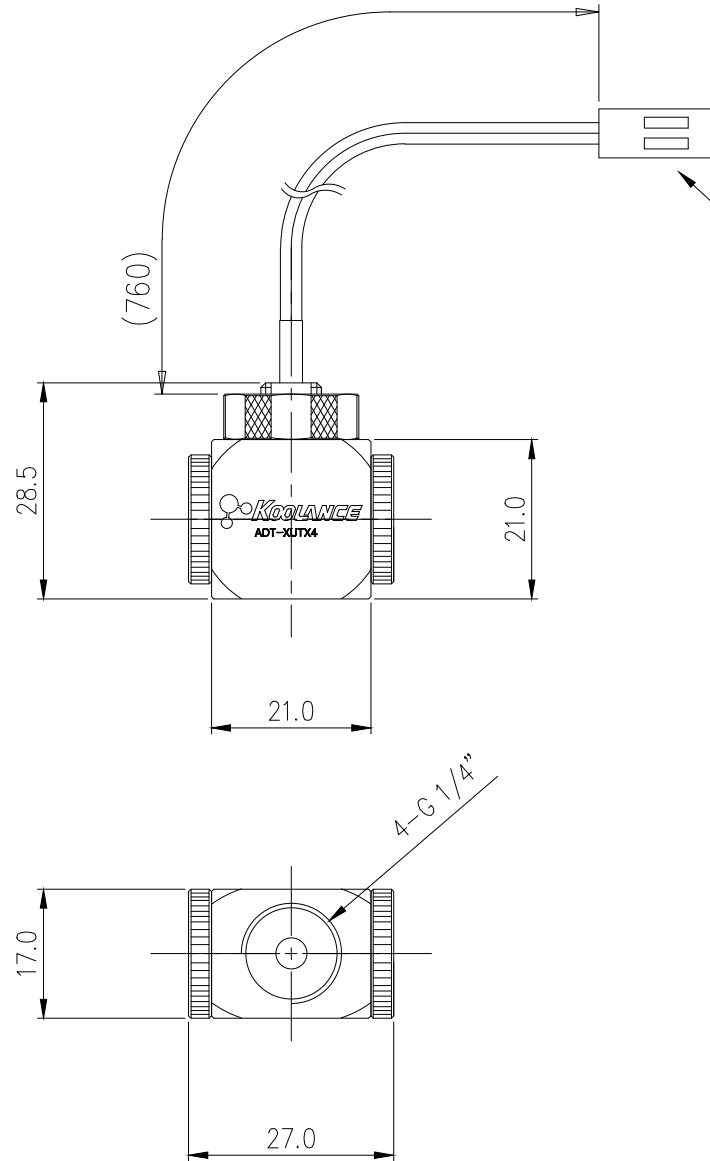

1x Housing : 6501-02 (Alex)  
2x Pin : 65T (Alex)

NO.	DESCRIPTION	MATER'L	QUANTITY	REMARKS
	<b>Koolance</b>	UNIT	MM	ITEM SEN-AP008B
		SCALE	N/S	TITLE
	BY	BY	BY	BY
	DATE	3RD ANGLE		Ass'y
APR.05.2021	S.J.LEE	CODE NO.	DWG. NO.	PAGE