


**P/N: SEN-TP010MFG**


**Coolant Temperature Sensor Inline,  
Male/Female Threads, 10K Ohm**



Coolant thermistor temperature sensor within a swiveling brass body. Male and female G 1/4 BSPP threads are provided on either end. Wire length = 30" (76cm). NOTE: This sensor will only work with Koolance products which use 10K Ohm @25° C sensors (first introduced in 2011).

General	
Weight	0.13 lb (0.06 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Nickel-Plated Brass, EPDM

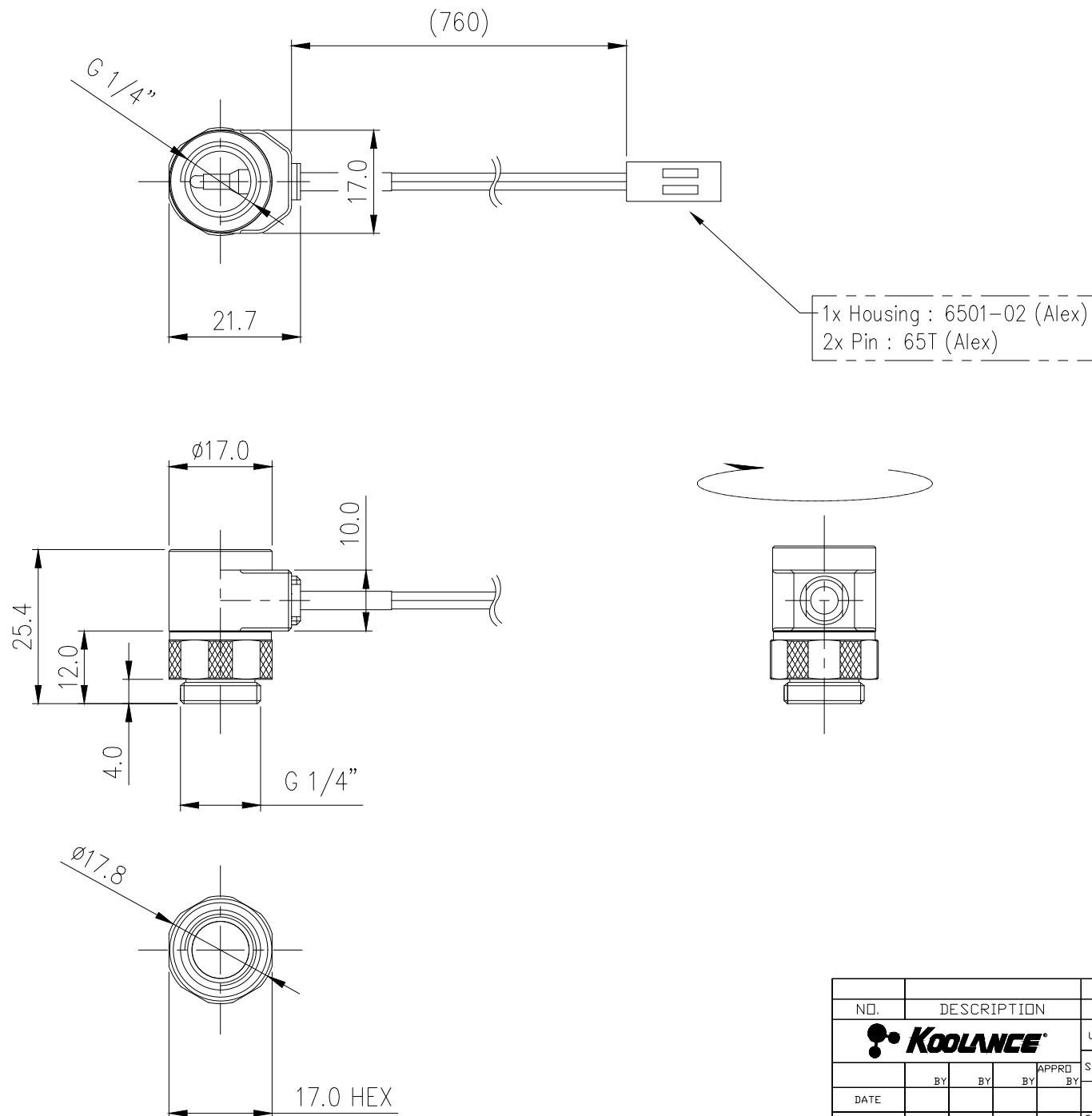

NO.		DESCRIPTION				MATER'L		QUANTITY		REMARKS	
 <b>KOOLANCE®</b>						UNIT		MM		ITEM SEN-TP010MFG	
						SCALE		N/S		TITLE	
						3RD ANGLE		Ass'y			
DATE		BY		BY		BY				APPRO BY	
APR.05.2021		S.J.LEE								CODE NO.	
										D'WG. NO.	
										PAGE	