


P/N: SEN-TP010MFG


**Coolant Temperature Sensor Inline,
Male/Female Threads, 10K Ohm**



Coolant thermistor temperature sensor within a swiveling brass body. Male and female G 1/4 BSPP threads are provided on either end. Wire length = 30" (76cm). NOTE: This sensor will only work with Koolance products which use 10K Ohm @25° C sensors (first introduced in 2011).

General	
Weight	0.13 lb (0.06 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Nickel-Plated Brass, EPDM

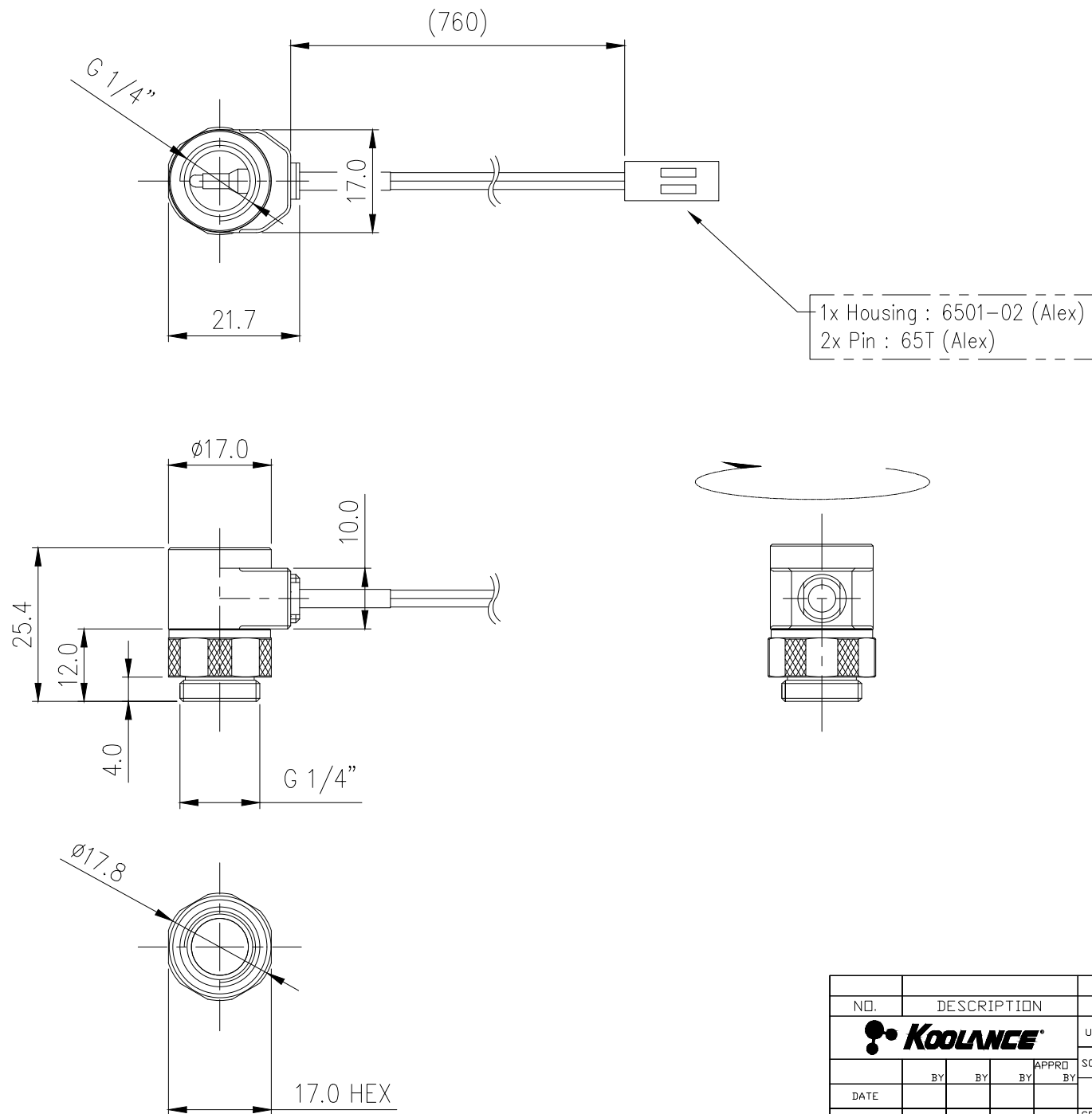

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS
 KOOLANCE®						UNIT	MM	ITEM SEN-TP010MFG	
					APPRO BY	SCALE	N/S	TITLE	
DATE		BY	BY	BY	BY	3RD ANGLE		Ass'y	
APR.05.2021		S.J.LEE				CODE NO.		DWG. NO.	
								PAGE	