




Coolant thermistor temperature sensor within a swiveling brass body. Male and female G 1/4 BSPP threads are provided on either end. Wire length = 30" (76cm). NOTE: This sensor will only work with Koolance products which use 10K Ohm @25° C sensors (first introduced in 2011).

General	
Weight	0.13 lb (0.06 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	8kgf/cm ² (113.8psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	Nickel-Plated Brass, EPDM

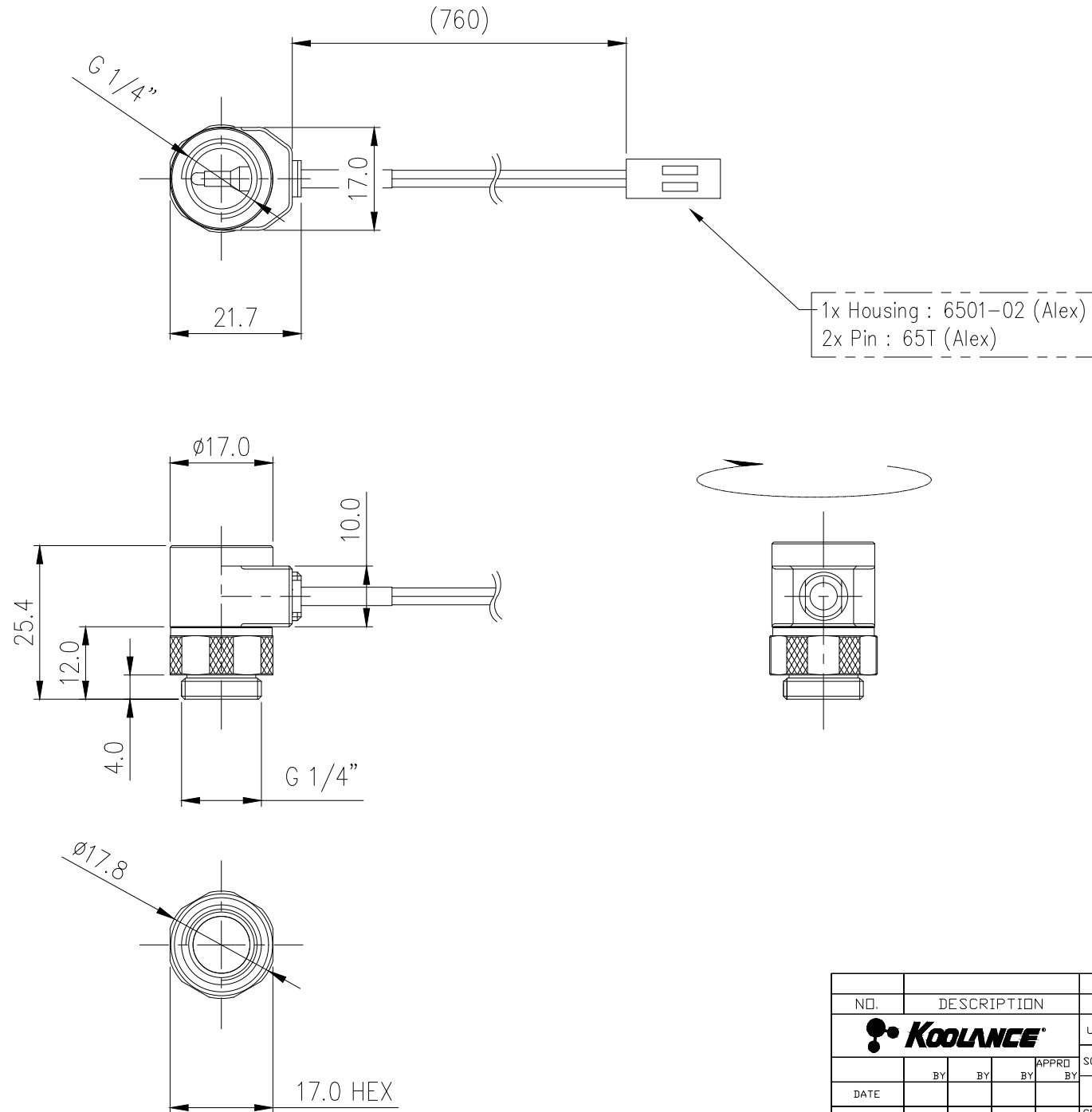

NO.	DESCRIPTION	MATER'L		QUANTITY	REMARKS
	KOOLANCE	UNIT	MM	ITEM	SEN-TP010MFG
		SCALE	N/S	TITLE	Ass'y
DATE	BY	BY	APPRO BY	BY	3RD ANGLE
APR.05.2021	S.J.LEE				CODE NO.
					DWG. NO.
					PAGE