



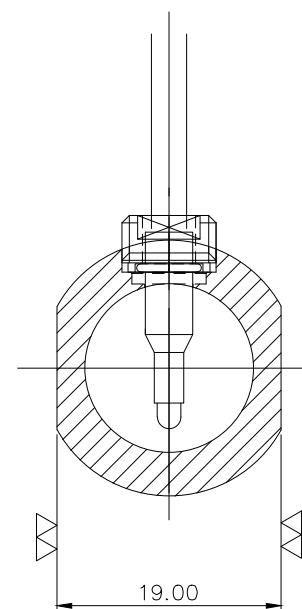


Coolant thermistor temperature sensor within nickel-plated brass body. G 1/4 BSPP threads are provided on both sides. Wire length = 30" (76cm). NOTE: This sensor will only work with Koolance products which use 10K Ohm @25°C sensors (first introduced in 2011).

General	
Weight	0.13 lb (0.06 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25°C	20kgf/cm ² (284.5psi)
Max Temperature Tolerance	120°C (248°F)
Wetted Materials	Brass, Nickel

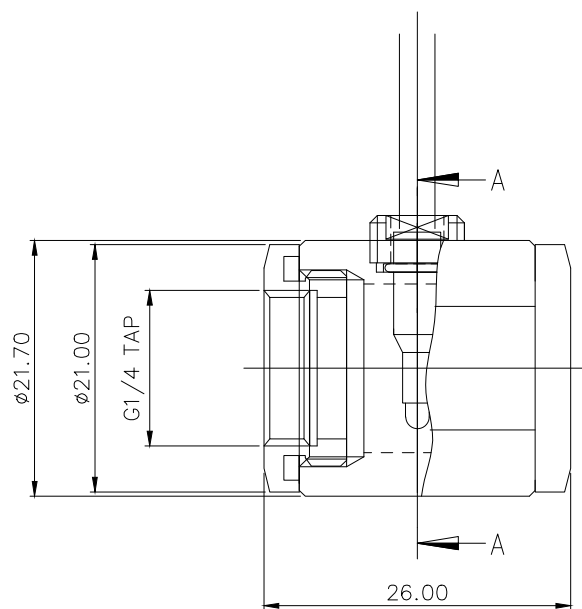

SECTION A-A

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS
 KOOLANCE®		APPRO BY				UNIT	MM	ITEM SEN-TPL010K	
						SCALE	N/S	TITLE	
						3RD ANGLE		Ass'y	
DATE	BY	BY	BY	CODE NO.		DWG. NO.	PAGE		
12.17.2021	YS.SHIN								