



www.koolance.com

Specifications Sheet

Generated: 2024-04-26

P/N: ADT-N38M-G14F-SS




Threading Adapter, NPT 3/8 Male to G 1/4  
Female, Stainless Steel



Single fitting threading adapter, from NPT 3/8 (male) to G 1/4 BSPP (female).



General	
Weight	0.05 lb (0.02 kg)
Fitting Thread	NPT 3/8, G 1/4 BSPP
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)
Wetted Materials	SUS 316, EPDM

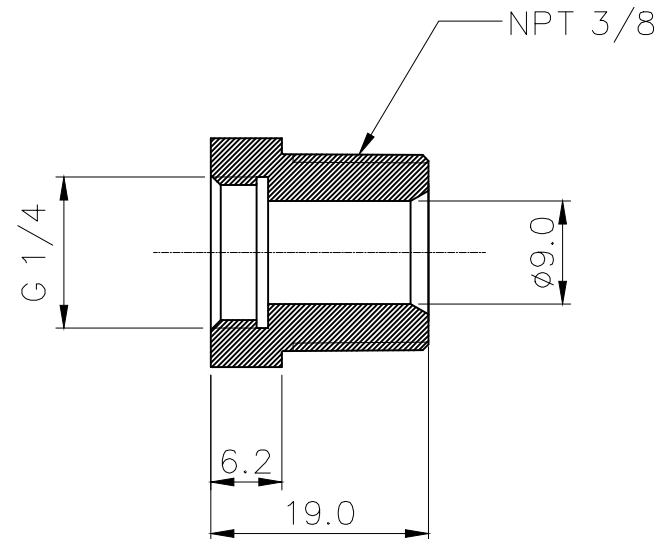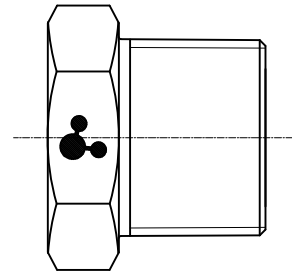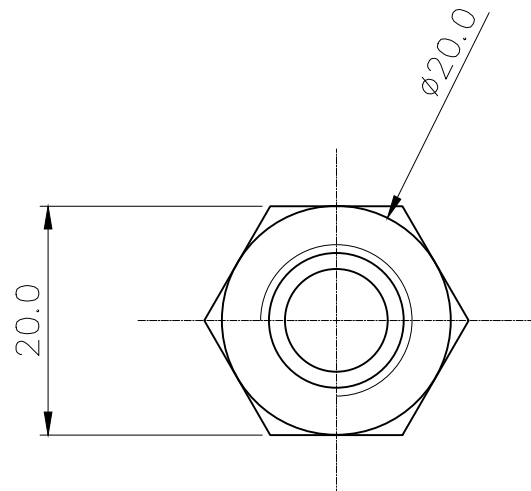

△						
REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY	
REVISION						

NO.		DESCRIPTION		MATER'L		QUANTITY	REMARKS
<b>KOOLANCE</b>		SCALE		UNIT	MM	ITEM	ADT-N38M-G14F-SS
				N/S		TITLE	M-F Type (NPT3/8-G1/4)
DATE	BY	BY	BY	APPRD BY		3RD ANGLE	
	ys.shir					CODE NO.	DWG. NO.
							PAGE
						-	