

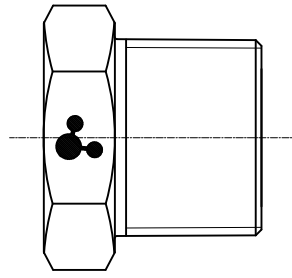


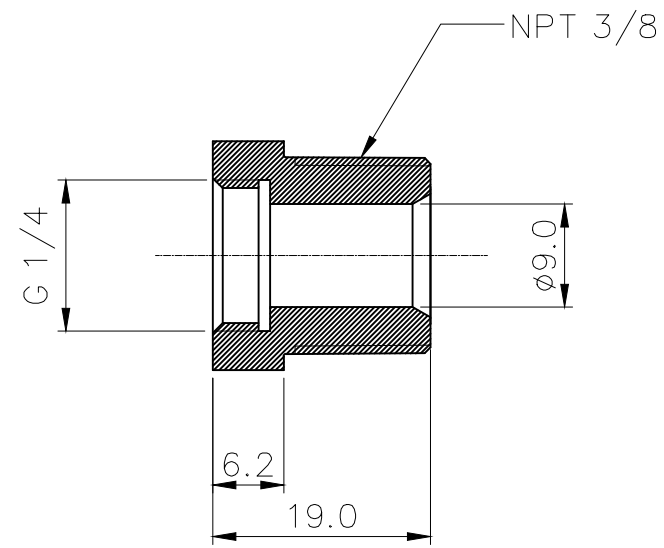

Thread adapter from NPT 3/8 (male) to G 1/4 BSPP (female).

General	
Weight	0.05 lb (0.02 kg)
Fitting Thread	NPT 3/8, G 1/4 BSPP
Max Pressure Tolerance @ 25 °C	15kgf/cm <sup>2</sup> (213.4psi)
Max Temperature Tolerance	120 °C (248 °F)
Wetted Materials	SUS 316, EPDM

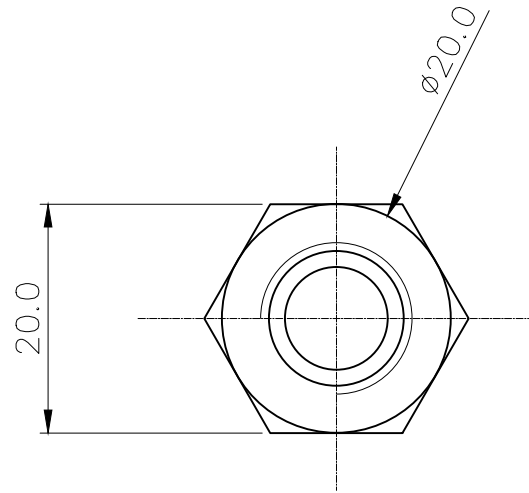

REV	DATE	CONTENTS	REVD BY	CHKD BY	APPD BY
REVISION					

NO.	DESCRIPTION			MATER'L		QUANTITY	REMARKS
	<b>KOLANCE</b>			UNIT	MM	ITEM	ADT-N38M-G14F-SS
				SCALE	N/S	TITLE	M-F Type (NPT3/8-G1/4)
DATE	BY	BY	BY	APPRD BY	BY	3RD ANGLE	
	ys.shir					CODE NO.	DWG. NO.
							PAGE
							-