

# P/N: HOS-06X10PU-CL-15M


Tubing, PU Clear, Dia: 06mm x 10mm (1/4in x 3/8in) - [Length 15m / 49.2ft]



Koolance clear polyurethane tubing with 6mm (1/4in) internal diameter, 10mm (3/8in) external diameter. Length 15m / 49.2ft. Bend radius is approximately 25mm (0.98in).


General	
Weight	0.04 lb (0.02 kg)
Max Pressure Tolerance @ 25 °C	7kgf/cm2 (99.6psi)
Max Temperature Tolerance	80 °C (176 °F)
Hardness (Shore)	85A

Ø 3/8 in (9.5mm)

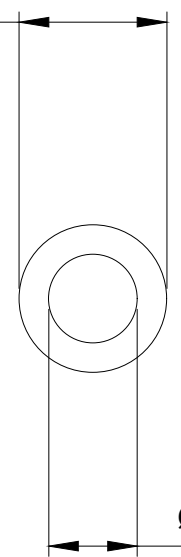


Ø 1/4 in (6.4mm)

LENGTH IS REPRESENTATIVE

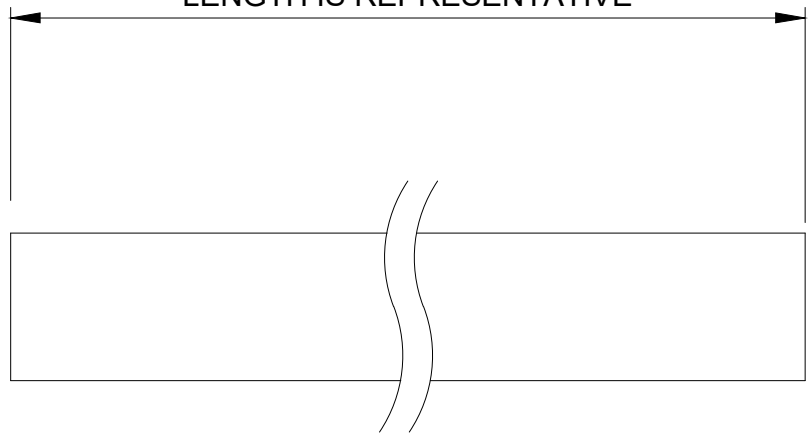

Clear polyurethane

NO.	DESCRIPTION				MATER'L		QUANTITY	REMARKS
					UNIT	inch	APPAR	
					SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRD BY	3RD ANGLE		HOS-06X10PU-CL-XX	
2026.05.11	SK.An				CODE NO.		DWG. NO.	