

P/N: HOS-06X10PU-CL- 100M


**Tubing Roll, PU Clear, Dia: 06mm x 10mm
(1/4in x 3/8in) - [Length 100m / 328ft]**



Koolance clear polyurethane tubing with 6mm (1/4in) internal diameter, 10mm (3/8in) external diameter. Bend radius is approximately 25mm (0.98in). This tubing is one roll of 100m (328ft).


General	
Weight	9.80 lb (4.45 kg)
Max Pressure Tolerance @ 25 °C	7kgf/cm ² (99.6psi)
Max Temperature Tolerance	80 °C (176 °F)
Hardness (Shore)	85A

Ø 3/8 in (9.5mm)

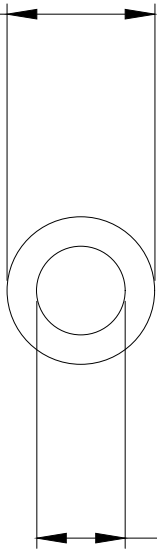


Ø 1/4 in (6.4mm)

LENGTH IS REPRESENTATIVE

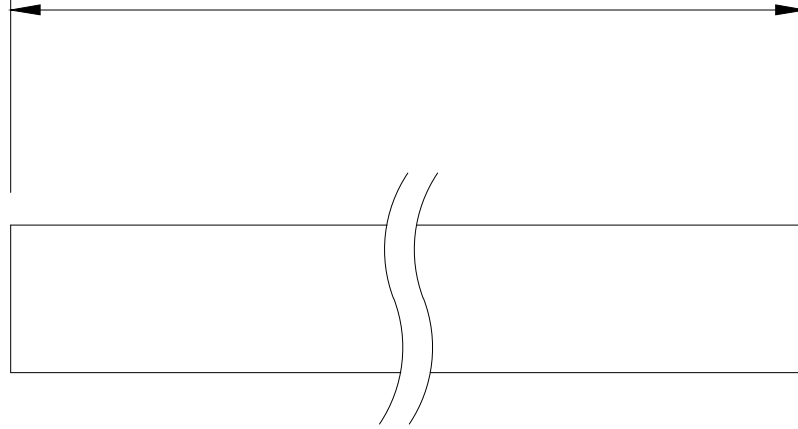

Clear polyurethane

NO.	DESCRIPTION				MATER'L		QUANTITY	REMARKS
					UNIT	inch	APPAR	
					SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRO BY	3RD ANGLE		HOS-06X10PU-CL-XX	
2026.05.11	SK.An				CODE NO.		DWG. NO.	