


Tubing, PVC Clear, Dia: 13mm x 16mm (1/2in x 5/8in) - [Length 15m / 49.2ft]



Koolance clear PVC tubing with 13mm (1/2in) internal diameter, 16mm (5/8in) external diameter. Length 15m / 49.2ft. Bend radius is approximately 55mm (2.2in).


General	
Weight	4.00 lb (1.81 kg)
Max Pressure Tolerance @ 25°C	4kgf/cm ² (57psi)
Max Temperature Tolerance	70°C (158°F)
Hardness (Shore)	75A

Ø 5/8 in(15.9mm)

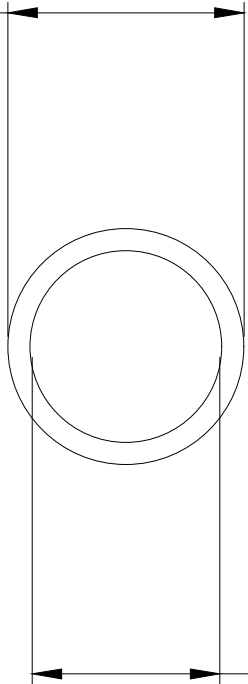


Ø 1/2 in(12.7mm)

LENGTH IS REPRESENTATIVE

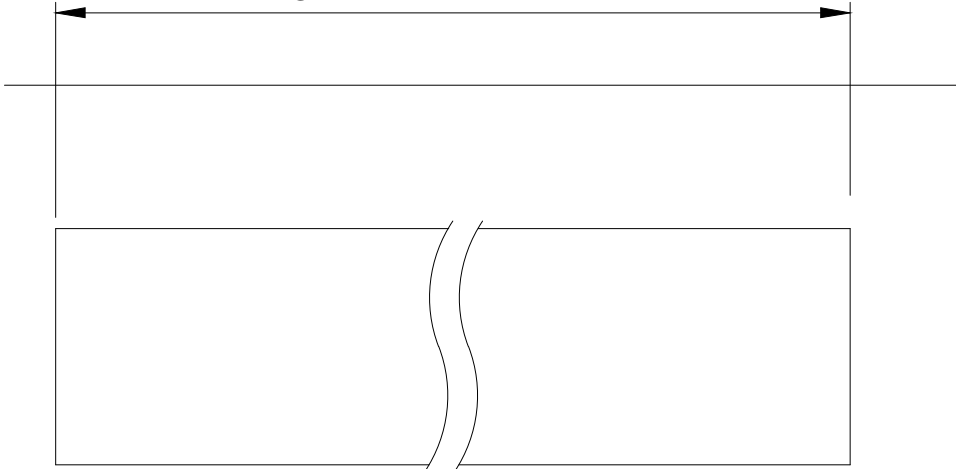

Clear PVC

NO.	DESCRIPTION				MATER'L		QUANTITY	REMARKS
					UNIT	inch	APPAR	
					SCALE	N/S	TITLE	
DATE	BY	BY	BY	APPRD BY	3RD ANGLE		HOS-13CL-XX	
2026.05.11	SK.An				CODE NO.		DWG. NO.	