

**Tubing, PVC Clear, Dia: 13mm x 19mm (1/2in x 3/4in), Ea: 305mm (1ft)**

Koolance clear PVC tubing with 13mm (1/2in) internal diameter, 19mm (3/4in) external diameter. Bend radius is approximately 35mm (1.4in). This tubing is priced per foot (305mm) and will be cut to the ordered length.




**Intended Tubing Size**

**ID:** 13mm (1/2")

**OD:** 19mm (3/4")

**Wall:** 3mm (1/8")

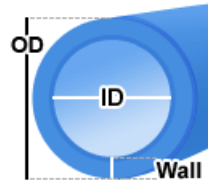

| General              |                    |
|----------------------|--------------------|
| Weight               | 0.14 lb (0.06 kg)  |
| Max Pressure @ 25 °C | 4.5kgf/cm2 (64psi) |
| Max Temperature      | 70 °C (158 °F)     |
| Hardness (Shore)     | 75A                |