

P/N: HOS-10X14EP-100M


Tubing, EPDM Black, Dia: 10mm x 14mm (3/8in x 9/16in) - [Length 100m / 328ft]



Koolance black EPDM non-reinforced tubing with 10mm (3/8in) internal diameter, 14mm (9/16in) external diameter. Length 100m / 328ft. Bend radius is approximately 40mm (1.58in).


General	
Weight	27.00 lb (12.25 kg)
Max Pressure Tolerance @ 25°C	7.1kgf/cm2 (101.5psi)
Max Temperature Tolerance	120°C (248°F)
Hardness (Shore)	70A

Ø 9/16 in (14.3mm)

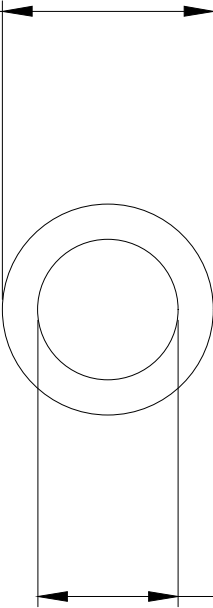

Ø 3/8 in (9.5mm)

LENGTH IS REPRESENTATIVE

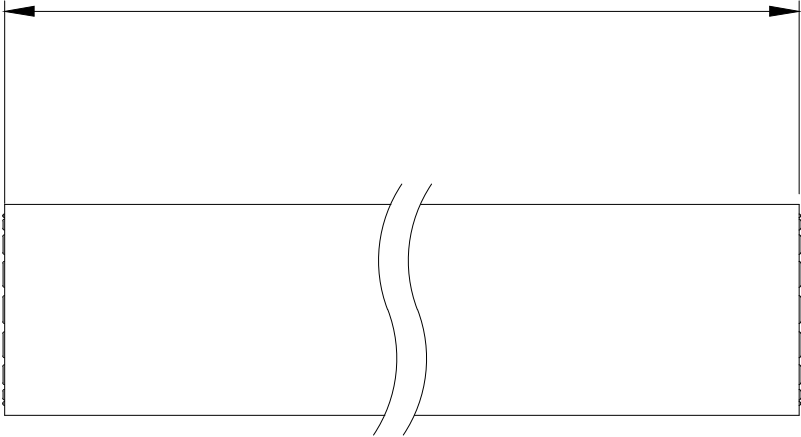

EPDM non-reinforced

NO.		DESCRIPTION				MATER'L		QUANTITY	REMARKS
						UNIT	inch	APPAR	
		BY	BY	BY	APPRO	SCALE	N/S	TITLE	
DATE					BY	3RD ANGLE		HOS-10X14EP-XX	
2026.05.11		SK.An				CODE NO.		DWG. NO.	