

# P/N: HOS-10X14EP-10M


**Tubing, EPDM Black, Dia: 10mm x 14mm (3/8in x 9/16in) - [Length 10m / 32.8ft]**



Koolance black EPDM non-reinforced tubing with 10mm (3/8in) internal diameter, 14mm (9/16in) external diameter. Length 10m / 32.8ft. Bend radius is approximately 40mm (1.58in).


General	
Weight	3.00 lb (1.36 kg)
Max Pressure Tolerance @ 25°C	7.1kgf/cm <sup>2</sup> (101.5psi)
Max Temperature Tolerance	120°C (248°F)
Hardness (Shore)	70A

Ø 9/16 in (14.3mm)

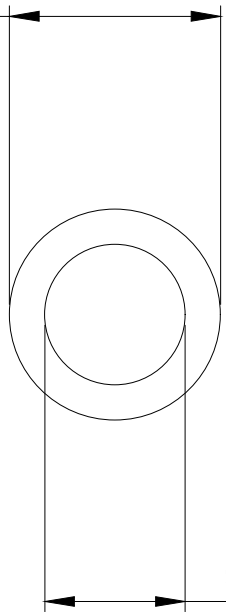

Ø 3/8 in (9.5mm)

LENGTH IS REPRESENTATIVE

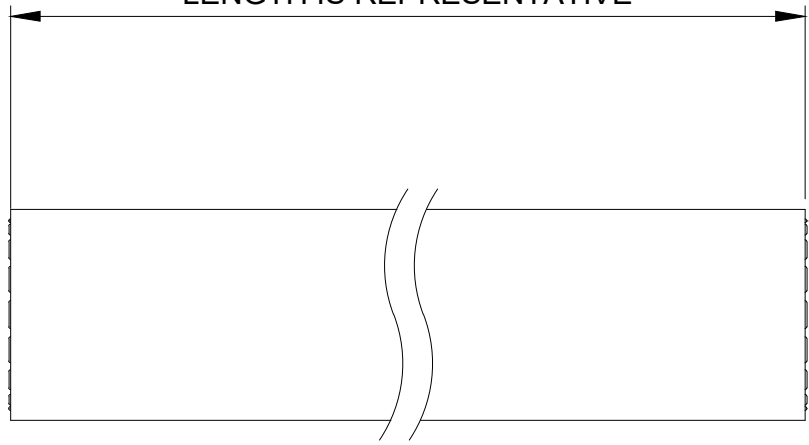

### EPDM non-reinforced

NO.	DESCRIPTION				MATER'L	QUANTITY	REMARKS
					UNIT	inch	APPAR
					SCALE	N/S	TITLE
DATE	BY	BY	BY	APPRD BY	3RD ANGLE		
2026.05.11	SK.An				CODE NO.	DWG. NO.	