




Koolance black EPDM non-reinforced tubing with 10mm (3/8in) internal diameter, 14mm (9/16in) external diameter. Length 3m / 9.8ft. Bend radius is approximately 40mm (1.58in).


General	
Weight	0.80 lb (0.36 kg)
Max Pressure Tolerance @ 25 °C	7.1kgf/cm2 (101.5psi)
Max Temperature Tolerance	120 °C (248 °F)
Hardness (Shore)	70A

Ø 9/16 in (14.3mm)

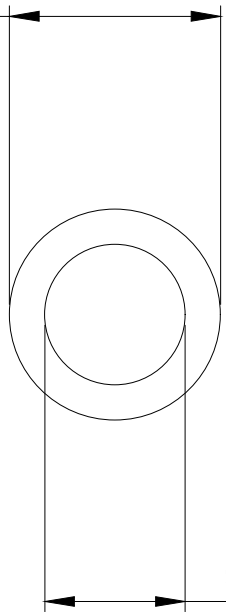

Ø 3/8 in (9.5mm)

LENGTH IS REPRESENTATIVE

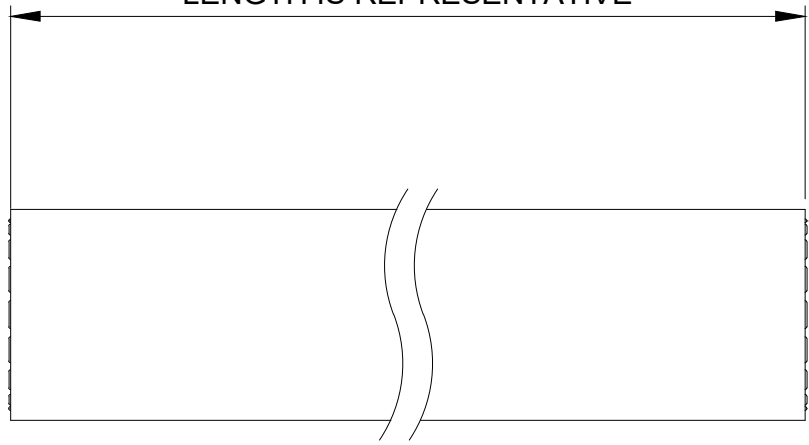

EPDM non-reinforced

NO.	DESCRIPTION				MATER'L		QUANTITY	REMARKS
					UNIT	inch	APPAR	
					SCALE	N/S	TITLE	HOS-10X14EP-XX
DATE	BY	BY	BY	APPRD BY	3RD ANGLE			
2026.05.11	SK.An				CODE NO.		DWG. NO.	