



P/N: HOS-13X21EP-10M

Hose, EPDM Black, Dia: 13mm x 21mm (1/2in x 13/16in) - [Length 10m / 32.8ft]



Koolance black EPDM thread-reinforced hose with 13mm (1/2in) internal diameter, 21mm (13/16in) external diameter. Length 10m / 32.8ft. Bend radius is approximately 50mm (1.97in).

General	
Weight	0.80 lb (0.36 kg)
Max Pressure Tolerance @ 25 °C	7.1kgf/cm2 (101.5psi)
Max Temperature Tolerance	120 °C (248 °F)
Hardness (Shore)	70A

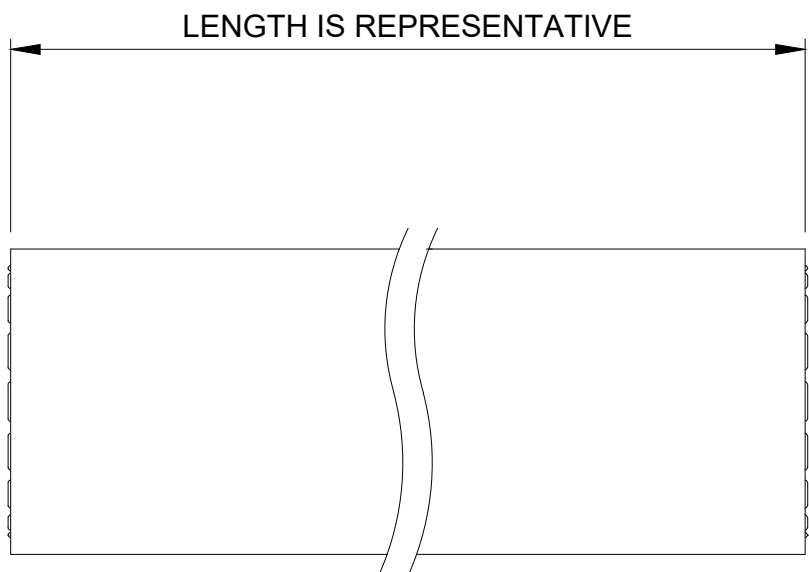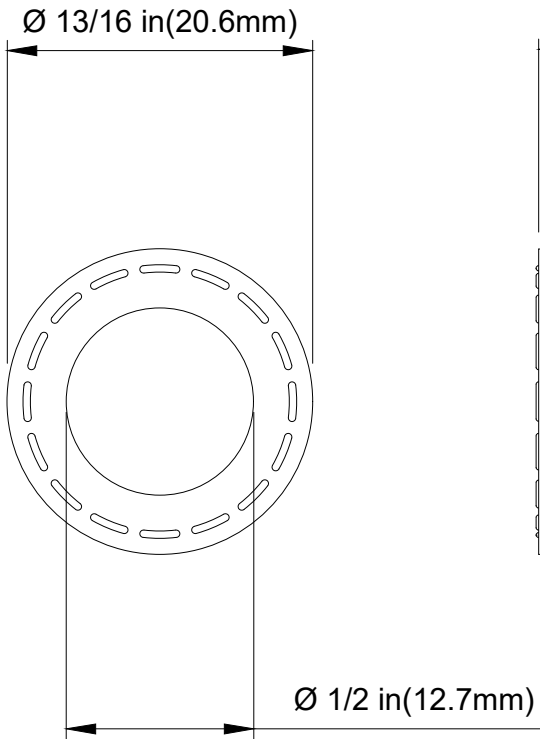

EPDM thread-reinforced

NO.	DESCRIPTION	MATER'L	QUANTITY	REMARKS
			UNIT	inch
			SCALE	N/S
			3RD ANGLE	
DATE	BY	BY	BY	APPRO BY
2026.05.11	SK.An			
			CODE NO.	DWG. NO.



TITLE
HOS-13X21EP-XX