




Koolance video bridge connectors link multiple video water blocks together with ease. CNT-VDB4 is for combining four (dual L-bracket) video blocks in consecutive PCI-Express slots. This version uses a combination serial+parallel flow path to minimize pressure drop. This product is only compatible with Koolance VID-series water blocks which have detachable fitting bases (launched in 2013 or later).

NOTE: Hose barbs are recommended for 10mm (3/8in) and 13mm (1/2in) ID tubing sizes to avoid conflicting with the water block or video card.

General	
Weight	0.91 lb (0.41 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25 °C	2kgf/cm2 (28.5psi)
Max Temp. Operating Tolerance	80 °C (176 °F)

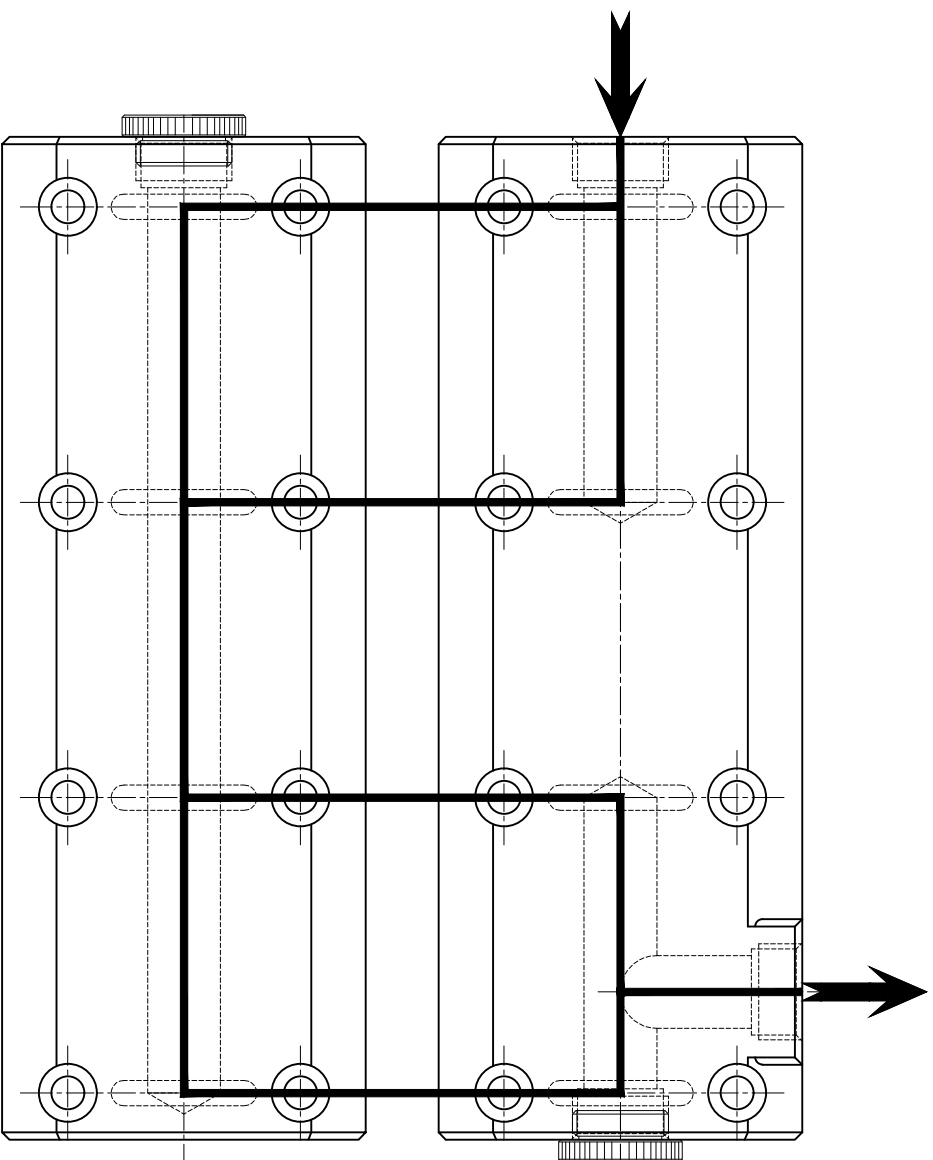

* Quad Semi-Parallel