


**VL2N Female Quick Disconnect No-Spill  
Coupling, Panel Barb for ID 06mm (1/4in)**




Koolance patented quick disconnect no-spill coupling with automatic shutoff. 6mm (1/4in) ID female panel-mountable hose barb with clamp. It will only fit a Koolance VL2N male quick disconnect.

After a quarter twist, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm<sup>2</sup> (7psi). Maximum operating pressure is 5kgf/cm<sup>2</sup> (71 psi). Maximum operating temperature is 90°C.

General	
Weight	0.09 lb (0.04 kg)

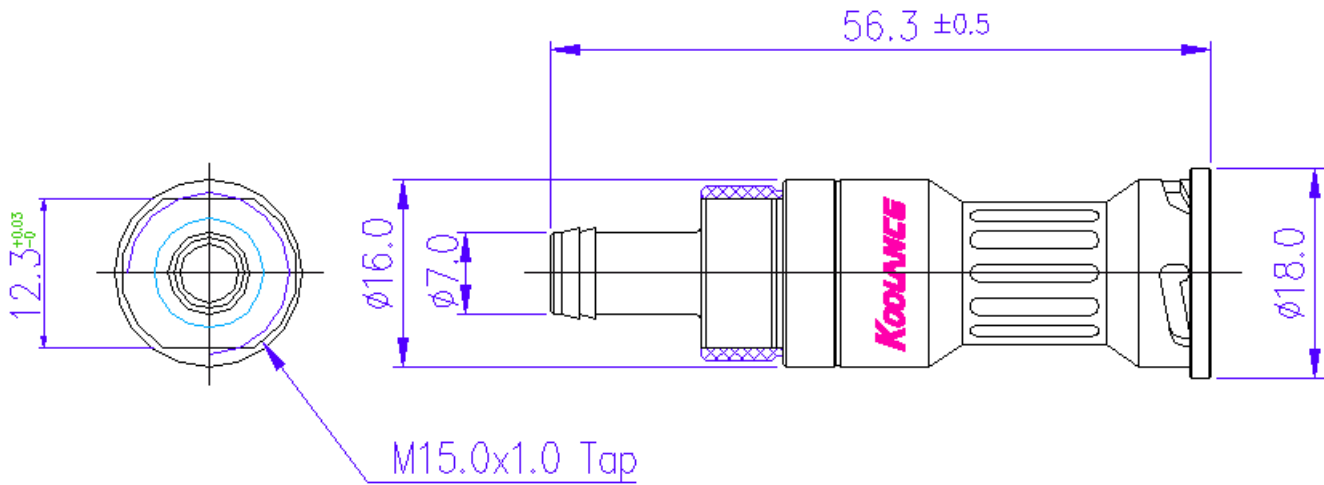

# No-Spill Shut-Off Valve

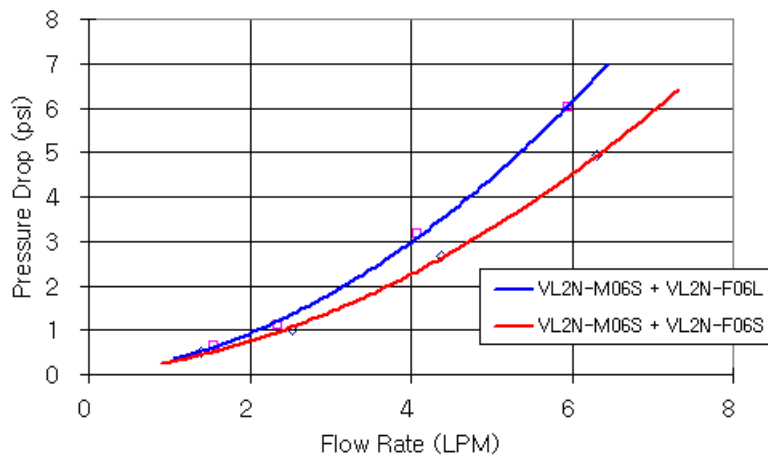

## Koolance "VL2N" 6mm or 10mm ID Panel Barb Hole Size

