

## VL3N Female Quick Disconnect No-Spill Coupling, for 10mm x 16mm (3/8in x 5/8in)




Koolance patented quick disconnect no-spill coupling with automatic shutoff. 10mm (3/8in) ID, 16mm (5/8in) OD female straight connection with compression fitting. It will only fit a Koolance VL3N male quick disconnect.

After a quarter twist, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm<sup>2</sup> (7psi). Maximum operating pressure is 2-2.5kgf/cm<sup>2</sup> (28-35 psi). Maximum operating temperature is 90°C.

### General

Weight	0.21 lb (0.10 kg)
--------	-------------------

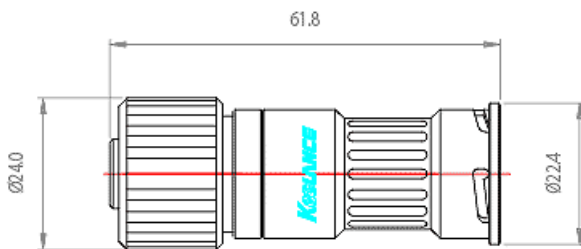

No-Spill Shut-Off Valve

